



Preferred ordering guide for NETCONNECT®

Australia

EDITION 5

COMMSCOPE®

Table of Contents

Copper Solutions	5
Category 6_A Shielded products	5
Category 6 _A F/UTP Cable	5
Category 6 _A Shielded Patch Panels	5
Category 6 _A Shielded Patch Panel Extras	5
Category 6 _A Shielded SLX/SL Series Jacks	6
Category 6 _A Shielded SLX/SL Series Jack Coloured Nose caps and SLX/SL Jack Bezels	6
Category 6 _A Shielded Standard Diameter Patch Cords	7
Category 6 _A Shielded Small Diameter Patch Cords	8
Category 6 _A Shielded System Leads	8
Category 6_A U/UTP products	9
Category 6 _A U/UTP Cable	9
Category 6 _A U/UTP Patch Panels	9
Category 6 _A U/UTP Patch Panels Extras	9
Category 6 _A U/UTP SL series Jack and Bezel Kits	10
Category 6 _A U/UTP SL series Jacks without Bezel	10
SLX/SL Jack Bezels	10
Category 6 _A U/UTP Standard Diameter Patch Cords	11
Category 6 _A U/UTP Small Diameter Patch Cords	12
Category 6 _A U/UTP System Leads	12
Category 6 U/UTP products	13
Category 6 U/UTP Cable	13
Category 6 U/UTP SL Patch Panels	13
Category 6 U/UTP Patch Panels Extras	13
Category 6 U/UTP SL Series Jack and Bezel Kits	14
Category 6 U/UTP SL Jacks without Bezel	14
SLX/SL Jack Bezels	14
Category 6 U/UTP Patch Cords	15
Category 6 U/UTP System Leads	15
Complementary Copper Solutions	16
Copper Tools	16
Horizontal Cable Management	16
SLX/SL Jack Bezels	16
Surface Mount Outlets (SL/SLX Jacks Only)	17
Consolidation Point	17
CCA (Ceiling Connector Assembly)	18
Patch Cord Modular Plug Coloured Boot Clips	18
HighBand® Solutions	19
HighBand Frames and Cable Management	19
HighBand Patch Cords	19

Table of Contents

Fibre Solutions	20
Fibre Optic Cables	20
Fibre Optics Cables - Internal	20
Fibre Optics Cables - External	20
Fibre Connectivity – Splice	21
FMS Rackmount Fibre Trays - 19"	21
EPX Rackmount Fibre Trays - 19"	21
AGILE G2 Connectorised Adaptor Packs	22
AGILE G2 Splice Tray, Glands and Accessories	22
AGILE G2 Wall Mounted Enclosures	23
AGILE G2 Wall Mounted Enclosure Splice/Adaptor Cassettes	23
Fibre Optic Pigtails	24
Powered Fibre Cable	24
POE Extenders	24
Fibre Connectivity - MPO*	25
EPX G2 Rackmount Fibre Trays - 19"	25
G2 MPO* Modules for Pre-terminated MPO Cables	25
Fibre Patch Cords	26
Fibre Optic Patch Cords UPC	26
Fibre Optic Patch Cords APC	27
Fibre MPO* Patch and Trunk Cables	28
MPO* Patch Cable, 3.2mm OSD, LSZH, OM4, 12 Fibre - Straight	28
MPO* Trunk Cable, 6.4mm OSD, LSZH, OM4, 12 Fibre - Straight	28
MPO* Patch Cable, 3.2mm OSD, LSZH, OS2, 12 Fibre - Straight	29
MPO* Trunk Cable, 6.4mm OSD, LSZH, OS2, 12 Fibre - Straight	29
Fibre Accessories	30
Fibre Optic Cleaning Accessories	30
Fibre Panel Accessories	30
Fibre Splicing Accessories	30

*CommScope's MPO solution complies with IEC 61754-7 MPO Connector Family. MTP componentry may be used in the multi-fibre connector.

The CommScope NETCONNECT ordering guide for the Australia region contains commonly ordered copper and fibre structured cabling products. This information is subject to change. For a comprehensive, up-to-date listing of CommScope products, please go to www.commscope.com

Copper Solutions

Category 6A F/UTP Products



Cat 6A F/UTP - White



Cat 6A F/UTP - Blue



Cat 6A F/UTP - External/ Underground

Category 6A F/UTP Cable (internal)

MID Part Number	Description
884024508/10	Cat 6A F/UTP Cable, 23AWG, OD 7.2mm, LSZH, White - 305mtr Reel
884028508/10	Cat 6A F/UTP Cable, 23AWG, OD 7.2mm, LSZH, Blue - 305mtr Reel

Other colours available on request - Black, Green, Grey, Pink, Violet, Yellow

Category 6A F/UTP Cable (external)

460158784	Cat 6A F/UTP Cable, 23AWG, OD 7.9mm, BLACK, Gel, PE Jacket (UV Resistant) - 305mtr Reel
-----------	---



Patch Panel Complete Kit



Recessed Angled Unloaded Panel



48 port 1RU Loaded Patch Panel

Category 6A Shielded SL Patch Panels

All panels terminated using SL Series Tool (MID Part Number: 1725150-6).

MID Part Number	Description	Type	Ports	Design
760242563	Patch Panel Kit, Cat 6A F/UTP 24 port FLUSH	Kit	24	Flush
760242564	Patch Panel Kit, Cat 6A F/UTP 24 port ANGLED	Kit	24	Angled
760237046	24 port STP Patch Panel, 19" - 1RU DDM FLUSH mount. UNLOADED.	Unloaded	24	Flush
760237048	24 port STP Patch Panel, 19" - 1RU DDM ANGLED. UNLOADED.	Unloaded	24	Angled
760237050	24 port STP Patch Panel, 19" - 1RU DDM Recessed ANGLED. UNLOADED.	Unloaded	24	Recessed
760237066	48 port STP Patch Panel, 19" - 1RU DDM Cat6A SL	Loaded	48	Flush
760245361	48 Port STP Patch Panel - ANGLED	Loaded	48	Angled



Patch Panel Label Kit



Rear Cable Manager Saddle Kit



Patch Panel SLX Jack, Black

Patch Panel Extras

All panels terminated using SL Series Tool (MID Part Number: 1725150-6).

MID Part Number	Description
760229179	Patch Panel Rear Saddle & Velcro Strap Kit
760244550	Universal Label Holder Kit for DDM Patch Panels. Packet of 4 labels for a 1 x DDM panel

Unloaded (DDM) panels use Shielded Cat 6A SL/SLX Jacks

2153449-2	Cat 6A RJ45 AMP-TWIST SLX Shielded Jack Black (MOQ = 24)
-----------	--

[Back to contents page](#)

Copper Solutions

Category 6A F/UTP Products



Cat 6_A SLX Shielded Jack Alpine White



Cat 6_A RJ45 SLX Shielded Jack Black – Bulk Pack (pack of 24)



Cat 6_A SLX Shielded Jack Black



KJX Series Modular Jack, RJ45, Cat6_A Shielded Side Entry, Silver



SLX 4 Direction Cable Exit Cap

Category 6A F/UTP Shielded SLX/SL Jacks

MID Part Number	Description
Terminated with SL Series Tool (MID Part Number: 1725150-6). Use CommScope SL/SLX Adaptor for Clipsal/HPM style face plates.	
1-2153449-3	Cat 6 _A RJ45 AMP-TWIST SLX Shielded Jack Alpine White without Dustcover (MOQ = 24)
4-2153449-2	Cat 6 _A RJ45 SLX Shielded Jack Black – Bulk Pack (pack of 24)
2153449-2	Cat 6 _A RJ45 AMP-TWIST SLX Shielded Jack Black without Dustcover (MOQ = 24)
2153449-4	Cat 6 _A RJ45 AMP-TWIST SLX Shielded Jack Grey without Dustcover (MOQ = 24)
760245049	Cat 6 _A Four-Direction Cable Exit Cap for SLX Jacks, (Bag of 50)
760254922	KJX Series Modular Jack, RJ45, Cat6A Shielded Side Entry, Silver
Note: SLX Jack colour options available upon request (Almond, Blue, Black, Green, Grey, Orange, Red, White, Yellow)	



Coloured Nose Caps for SLX Jacks



Clipsal/ HPM Bezels for SL Jacks

Coloured Nose Caps to suit SLX Series Jacks

MID Part Number	Description
2848025-5	COLOUR CAP, SLX Orange (Bag of 50)
2848025-6	COLOUR CAP, SLX Blue (Bag of 50)
2848025-7	COLOUR CAP, SLX Red (Bag of 50)
2848025-8	COLOUR CAP, SLX Yellow (Bag of 50)
2848025-9	COLOUR CAP, SLX Green (Bag of 50)

Adaptor Bezels for SL/SLX Series Jacks

CommScope SL/SLX Adaptor for Clipsal/HPM style face plates

64671116-02	Adaptor Clip - White. Use to mount SL/SLX Jacks into Clipsal/ HPM Faceplate Bag of 10
64671116-00	Adapter Clip - Black. Use to mount SL/SLX Jacks into Clipsal/ HPM Faceplate Bag of 10
64671116-07SH	Adaptor Clip - White. WITH SHUTTER. Use to mount SL/SLX Jacks into Clipsal/HPM Faceplate Bag of 10

[Back to contents page](#)

Copper Solutions

Category 6A F/UTP Products



Cat 6A Shielded Patch Cord

Category 6A S/FTP Patch Cords (LSZH)	
MID Part Number	Description
Patch cords have outside diameter of 5.9mm. Other colours and lengths available	
NPC6ASZDB-BL050C	Cat 6A S/FTP, RJ45, Patch Cord, LSZH, Blue - 0.2 mtr
NPC6ASZDB-BL050C	Cat 6A S/FTP, RJ45, Patch Cord, LSZH, Blue - 0.5 mtr
NPC6ASZDB-BL001M	Cat 6A S/FTP, RJ45, Patch Cord, LSZH, Blue - 1 mtr
NPC6ASZDB-BL150C	Cat 6A S/FTP, RJ45, Patch Cord, LSZH, Blue - 1.5 mtr
NPC6ASZDB-BL002M	Cat 6A S/FTP, RJ45, Patch Cord, LSZH, Blue - 2 mtr
NPC6ASZDB-BL003M	Cat 6A S/FTP, RJ45, Patch Cord, LSZH, Blue - 3 mtr
NPC6ASZDB-BL005M	Cat 6A S/FTP, RJ45, Patch Cord, LSZH, Blue - 5 mtr
NPC6ASZDB-BL010M	Cat 6A S/FTP, RJ45, Patch Cord, LSZH, Blue - 10 mtr
NPC6ASZDB-WT020C	Cat 6A S/FTP, RJ45, Patch Cord, LSZH, White - 0.2 mtr
NPC6ASZDB-WT050C	Cat 6A S/FTP, RJ45, Patch Cord, LSZH, White - 0.5 mtr
NPC6ASZDB-WT001M	Cat 6A S/FTP, RJ45, Patch Cord, LSZH, White - 1 mtr
NPC6ASZDB-WT150C	Cat 6A S/FTP, RJ45, Patch Cord, LSZH, White - 1.5 mtr
NPC6ASZDB-WT002M	Cat 6A S/FTP, RJ45, Patch Cord, LSZH, White - 2 mtr
NPC6ASZDB-WT003M	Cat 6A S/FTP, RJ45, Patch Cord, LSZH, White - 3 mtr
NPC6ASZDB-WT005M	Cat 6A S/FTP, RJ45, Patch Cord, LSZH, White - 5 mtr
NPC6ASZDB-WT010M	Cat 6A S/FTP, RJ45, Patch Cord, LSZH, White - 10 mtr
For other colours, ie: NPC6ASZDB-XX, where XX use: BK=Black, GR=Green, GY=Grey, OR=Orange, RD=Red, VL=Violet, YL=Yellow	

[Back to contents page](#)

Copper Solutions

Category 6A F/UTP Products

Category 6A SYSTEM LEADS F/UTP Solid	
MID Part Number	Description
NCC44FZDB-08M020	Cat 6A SYSTEM LEAD F/UTP, solid, LSZH, White, 20m
NCC44FZDB-08M030	Cat 6A SYSTEM LEAD F/UTP, solid, LSZH, White, 30m
NCC44FZDB-08M040	Cat 6A SYSTEM LEAD F/UTP, solid, LSZH, White, 40m
NCC44FZDB-08M050	Cat 6A SYSTEM LEAD F/UTP, solid, LSZH, White, 50m
NCC44FZDB-08M060	Cat 6A SYSTEM LEAD F/UTP, solid, LSZH, White, 60m

[Back to contents page](#)

Copper Solutions

Category 6A U/UTP Products



Cat 6_A U/UTP Cable

Category 6 _A U/UTP Cable	
MID Part Number	Description
884041004/10	Cat 6 _A Cable 4 Pair UTP Solid LSZH. 305mtr Reel - BLUE 6.9mm OD, 24AWG
884045804/10	Cat 6 _A Cable 4 Pair UTP Solid LSZH. 305mtr Reel - GREY 6.9mm OD, 24AWG



Patch Panel Complete Kit



Recessed Angled Unloaded Panel



Patch Panel Complete Kit

Category 6 _A U/UTP SL Patch Panel KITS				
All panels terminated using SL Series Tool (MID Part Number: 1725150-6).				
MID Part Number	Description	Type	Ports	Design
760242560	24 port UTP Patch Panel Kit, 1RU Cat 6 _A FLUSH	Kit	24	Flush
760242561	24 port UTP Patch Panel Kit, 1RU Cat 6 _A ANGLED	Kit	24	Angled
760237040	24 port UTP Patch Panel, 1RU DDM FLUSH - Unloaded	Unloaded	24	Flush
760237042	24 port UTP Patch Panel, 1RU DDM ANGLED - Unloaded	Unloaded	24	Angled
760237044	24 port UTP Patch Panel, 1RU DDM RECESSED ANGLED - Unloaded	Unloaded	24	Recessed



Patch Panel Label Kit



Rear Cable Manager Saddle Kit



Patch Panel SLX Jack, Black

Patch Panel Extras	
Rear Saddle Cable management kit required for all unloaded panels	
MID Part Number	Description
760229179	Patch Panel Rear Saddle & Velcro Strap Kit
760244550	Universal Label Holder Kit for DDM Patch Panels. Packet of 4 labels for a 1 x DDM panel
Unloaded (DDM) panels use Cat 6A SL UTP Jacks	
760241195	Cat 6 _A RJ45 AMP-TWIST SL UTP Jack Black (MOQ = 24)

[Back to contents page](#)

Copper Solutions

Category 6A U/UTP Products



Cat 6_A UTP FMK10G Jack with Bezel



Cat 6_A UTP FMK10G Jack with Shuttered Bezel



Cat 6_A SL110G without Bezel



Category 6_A U/UTP SL Series Jack and Bezel Kits

MID Part Number	Description
Terminated with SL Series Tool (MID Part Number: 1725150-6). Use CommScope SL/SLX Adaptor for Clipsal/HPM style face plates.	
760241220	Cat 6 _A UTP FMK10G modular jack - ALPINE WHITE (Bezel and Jack Kit)
760241221	Cat 6 _A UTP FMK10G modular jack - ALPINE WHITE (SHUTTERED Bezel and Jack Kit)
760241219	Cat 6 _A UTP FMK10G modular jack - BLACK (Bezel and Jack Kit)

Category 6_A U/UTP SL Series Jack without Bezel

MID Part Number	Description
760241194	Cat 6 _A SL10G SL110 UTP jack - ALPINE WHITE
760241195	Cat 6 _A SL10G SL110 UTP jack - BLACK
Note: Cat 6 _A SL110G Jack colour options available upon request (Almond, Blue, Black, Green, Grey, Orange, Red, Violet, White, Yellow)	



Clipsal/HPM Bezels for SL Jacks

Adaptor Bezels for SL/SLX Series Jacks

CommScope SL/SLX Adaptor for Clipsal/HPM style face plates	
64671116-02	Adaptor Clip - White. Use to mount SL/SLX Jacks into Clipsal/ HPM Faceplate Bag of 10
64671116-00	Adapter Clip - Black. Use to mount SL/SLX Jacks into Clipsal/ HPM Faceplate Bag of 10
64671116-07SH	Adaptor Clip - White. WITH SHUTTER. Use to mount SL/SLX Jacks into Clipsal/HPM Faceplate Bag of 10

[Back to contents page](#)

Copper Solutions

Category 6A U/UTP Products



Cat 6A U/UTP Patch Cord

Category 6A U/UTP Patch Cords (LSZH)	
MID Part Number	Description
Patch cords have outside diameter of 7.2mm	
NPC6AUZDB-BL001M	Cat 6 _A RJ45 Unshielded Patch Cord (LSZH) Blue (1.0M)
NPC6AUZDB-BL150C	Cat 6 _A RJ45 Unshielded Patch Cord (LSZH) Blue (1.5M)
NPC6AUZDB-BL002M	Cat 6 _A RJ45 Unshielded Patch Cord (LSZH) Blue (2.0M)
NPC6AUZDB-BL003M	Cat 6 _A RJ45 Unshielded Patch Cord (LSZH) Blue (3.0M)
NPC6AUZDB-BL005M	Cat 6 _A RJ45 Unshielded Patch Cord (LSZH) Blue (5.0M)
NPC6AUZDB-BL010M	Cat 6 _A RJ45 Unshielded Patch Cord (LSZH) Blue (10M)
NPC6AUZDB-BL015M	Cat 6 _A RJ45 Unshielded Patch Cord (LSZH) Blue (15M)
NPC6AUZDB-BL020M	Cat 6 _A RJ45 Unshielded Patch Cord (LSZH) Blue (20M)
NPC6AUZDB-WT001M	Cat 6 _A RJ45 Unshielded Patch Cord (LSZH) White (1.0M)
NPC6AUZDB-WT150C	Cat 6 _A RJ45 Unshielded Patch Cord (LSZH) White (1.5M)
NPC6AUZDB-WT002M	Cat 6 _A RJ45 Unshielded Patch Cord (LSZH) White (2.0M)
NPC6AUZDB-WT003M	Cat 6 _A RJ45 Unshielded Patch Cord (LSZH) White (3.0M)
NPC6AUZDB-WT005M	Cat 6 _A RJ45 Unshielded Patch Cord (LSZH) White (5.0M)
NPC6AUZDB-WT010M	Cat 6 _A RJ45 Unshielded Patch Cord (LSZH) White (10M)
NPC6AUZDB-WT015M	Cat 6 _A RJ45 Unshielded Patch Cord (LSZH) White (15M)
NPC6AUZDB-WT020M	Cat 6 _A RJ45 Unshielded Patch Cord (LSZH) White (20M)
For other colours, ie: NPC6AUZDB-XX, where XX use: BK=Black, GR=Green, GY=Grey, OR=Orange, RD=Red, YL=Yellow	

[Back to contents page](#)

Copper Solutions

Category 6A U/UTP Products



Cat 6A U/UTP Mini Patch Cord

Category 6A UTP SLIM Patch Cords (LSZH) 28AWG 4.95mm

MID Part Number	Description
CO199K2-0ZM001	Cat 6 _A RJ45 Unshielded Small Diameter MiNo6A Patch Cord (LSZH) Blue (1m)
CO199K2-0ZM002	Cat 6 _A RJ45 Unshielded Small Diameter MiNo6A Patch Cord (LSZH) Blue (2m)
CO199K2-0ZM003	Cat 6 _A RJ45 Unshielded Small Diameter MiNo6A Patch Cord (LSZH) Blue (3m)
CO199K2-0ZM004	Cat 6 _A RJ45 Unshielded Small Diameter MiNo6A Patch Cord (LSZH) Blue (4m)
CO199K2-0ZM007	Cat 6 _A RJ45 Unshielded Small Diameter MiNo6A Patch Cord (LSZH) Blue (7m)
CO199K2-0ZM010	Cat 6 _A RJ45 Unshielded Small Diameter MiNo6A Patch Cord (LSZH) Blue (10m)
CO199K2-0ZM015	Cat 6 _A RJ45 Unshielded Small Diameter MiNo6A Patch Cord (LSZH) Blue (15m)
CO199K2-08M001	Cat 6 _A RJ45 Unshielded Small Diameter MiNo6A Patch Cord (LSZH) White (1m)
CO199K2-08M002	Cat 6 _A RJ45 Unshielded Small Diameter MiNo6A Patch Cord (LSZH) White (2m)
CO199K2-08M003	Cat 6 _A RJ45 Unshielded Small Diameter MiNo6A Patch Cord (LSZH) White (3m)
CO199K2-08M004	Cat 6 _A RJ45 Unshielded Small Diameter MiNo6A Patch Cord (LSZH) White (4m)
CO199K2-08M007	Cat 6 _A RJ45 Unshielded Small Diameter MiNo6A Patch Cord (LSZH) White (7m)
CO199K2-08M010	Cat 6 _A RJ45 Unshielded Small Diameter MiNo6A Patch Cord (LSZH) White (10m)
CO199K2-08M015	Cat 6 _A RJ45 Unshielded Small Diameter MiNo6A Patch Cord (LSZH) White (15m)
Other colours available (CO199K2-01=Black, 03=Grey, 04=Spring Green, 07=Red, 09=Yellow, 0L=Violet)	

Category 6A SYSTEM LEADS UTP Solid

MID Part Number	Description
NPC6AUZDA-BL020M	Cat 6 _A SYSTEM LEAD UTP, solid, LSZH, A-Wired, Blue, 20m
NPC6AUZDA-BL030M	Cat 6 _A SYSTEM LEAD UTP, solid, LSZH, A-Wired, Blue, 30m
NPC6AUZDA-GY020M	Cat 6 _A SYSTEM LEAD UTP, solid, LSZH, A-Wired, Grey, 20m
NPC6AUZDA-GY030M	Cat 6 _A SYSTEM LEAD UTP, solid, LSZH, A-Wired, Grey, 30m

[Back to contents page](#)

Copper Solutions

Category 6 U/UTP Products



Cat 6 U/UTP Reel in a Box



Cat 6 U/UTP REELSPEED

Category 6 U/UTP Cable	
MID Part Number	Description
REELSPEED Cable Reel - Interlocking Exo-skeleton	
64991030-01A	Cat 6 U/UTP Cable, 23AWG, OD 6.4mm, GREY. REELSPEED. 305mtr
64991030-03A	Cat 6 U/UTP Cable, 23AWG, OD 6.4mm, BLUE. REELSPEED. 305mtr
Standard Cable Reel-in-a-box	
64991030-01AB	Cat 6 U/UTP Cable, 23AWG, OD 6.4mm, GREY. Reel in a box. 305mtr
64991030-03AB	Cat 6 U/UTP Cable, 23AWG, OD 6.4mm, BLUE. Reel in a box. 305mtr



Patch Panel Complete Kit



Recessed Angled Unloaded Panel



Flush Mount

Category 6 U/UTP SL Patch Panels				
All panels terminated using SL Series Tool (MID Part Number: 1725150-6).				
MID Part Number	Description	Type	Ports	Design
760242562	24 port Patch Panel Kit, Cat 6 UTP 24 port FLUSH	Kit	24	Flush
760237040	24 port UTP Patch Panel, 1RU DDM FLUSH - Unloaded	Unloaded	24	Flush
760237042	24 port UTP Patch Panel, 1RU DDM ANGLED - Unloaded	Unloaded	24	Angled
760237044	24 port UTP Patch Panel, 1RU DDM RECESSED ANGLED - Unloaded	Unloaded	24	Recessed



Patch Panel Label Kit



Rear Cable Manager Saddle Kit



Patch Panel SLX Jack, Black

Patch Panel Extras	
Rear Saddle Cable management kit required for all unloaded panels	
MID Part Number	Description
760229179	Patch Panel Rear Saddle & Velcro Strap Kit
760244550	Universal Label Holder Kit for DDM Patch Panels. Packet of 4 labels for a 1 x DDM panel
Unloaded (DDM) panels use Cat 6 SL UTP Jacks	
9-1375055-2	Cat 6 UTP RJ45 SL Jack, T568A or T568B - Black (MOQ = 24)

[Back to contents page](#)

Copper Solutions

Category 6 U/UTP Products



Cat 6 SL UTP Jack with Bezel

Cat 6 SL UTP plus Shuttered Bezel

Cat 6 SL UTP Jack without Bezel

Category 6 U/UTP SL Jack and Bezel Kits

MID Part Number	Description
SL Series suits Clipsal/HPM, Bag of 10 and includes Bezel/Adaptor Terminated with SL Series Tool (MID Part Number: 1725150-6).	
760238472	Cat 6 UTP RJ45 SL Jack, T568A or T568B - WHITE. Plus Clipsal/ HPM Style adaptor. (MOQ = 10)
760238471	Cat 6 UTP RJ45 SL Jack, T568A or T568B - BLACK. Plus Clipsal/ HPM Style adaptor. (MOQ = 10)
760238473	Cat 6 UTP RJ45 SL Jack, T568A or T568B - WHITE. Plus Clipsal/ HPM Style with shutter. (MOQ = 10)

Category 6 U/UTP SL Jacks without Bezel

MID Part Number	Description
1-1375055-3	Cat 6 UTP RJ45 SL Jack, T568A or T568B - WHITE
1375055-2	Cat 6 UTP RJ45 SL Jack, T568A or T568B - BLACK
1375055-4	Cat 6 UTP RJ45 SL Jack, T568A or T568B - GREY
1375055-5	Cat 6 UTP RJ45 SL Jack, T568A or T568B - ORANGE
1375055-6	Cat 6 UTP RJ45 SL Jack, T568A or T568B - BLUE
1375055-7	Cat 6 UTP RJ45 SL Jack, T568A or T568B - RED
1375055-8	Cat 6 UTP RJ45 SL Jack, T568A or T568B - YELLOW
1375055-9	Cat 6 UTP RJ45 SL Jack, T568A or T568B - GREEN
1-1375055-0	Cat 6 UTP RJ45 SL Jack, T568A or T568B - VIOLET



Clipsal/HPM Bezels for SL Jacks

Adaptor Bezels for SL/SLX Series Jacks

CommScope SL/SLX Adaptor for Clipsal/HPM style face plates	
64671116-02	Adaptor Clip - White. Use to mount SL/SLX Jacks into Clipsal/ HPM Faceplate Bag of 10
64671116-00	Adapter Clip - Black. Use to mount SL/SLX Jacks into Clipsal/ HPM Faceplate Bag of 10
64671116-07SH	Adaptor Clip - White. WITH SHUTTER. Use to mount SL/SLX Jacks into Clipsal/HPM Faceplate Bag of 10

[Back to contents page](#)

Copper Solutions

Category 6 U/UTP Products



Cat 6 U/UTP Patch Cord

Category 6 U/UTP Patch Cords 24AWG 5.97mm	
MID Part Number	Description
Patch cords have outside diameter of 5.97mm. Other colours and lengths available	
NPC06UVDB-BL003F	Cat6 RJ45 Patch Cord, Unshielded, CM (PVC), Blue, 3FT (0.9M)
NPC06UVDB-BL005F	Cat6 RJ45 Patch Cord, Unshielded, CM (PVC), Blue, 5FT (1.5M)
NPC06UVDB-BL007F	Cat6 RJ45 Patch Cord, Unshielded, CM (PVC), Blue, 7FT (2.1M)
NPC06UVDB-BL010F	Cat6 RJ45 Patch Cord, Unshielded, CM (PVC), Blue, 10FT (3.0M)
NPC06UVDB-BL016F	Cat6 RJ45 Patch Cord, Unshielded, CM (PVC), Blue, 16FT (4.8M)
NPC06UVDB-BL033F	Cat6 RJ45 Patch Cord, Unshielded, CM (PVC), Blue, 33FT (10.0M)
NPC06UVDB-WT003F	Cat6 RJ45 Patch Cord, Unshielded, CM (PVC), White, 3FT (0.9M)
NPC06UVDB-WT005F	Cat6 RJ45 Patch Cord, Unshielded, CM (PVC), White, 5FT (1.5M)
NPC06UVDB-WT007F	Cat6 RJ45 Patch Cord, Unshielded, CM (PVC), White, 7FT (2.1M)
NPC06UVDB-WT010F	Cat6 RJ45 Patch Cord, Unshielded, CM (PVC), White, 10FT (3.0M)
NPC06UVDB-WT016F	Cat6 RJ45 Patch Cord, Unshielded, CM (PVC), White, 16FT (4.8M)
NPC06UVDB-WT033F	Cat6 RJ45 Patch Cord, Unshielded, CM (PVC), White, 33FT (10.0M)
For other colours, ie: NPC06UVDB-XX, where XX use: BK=Black, GR=Green, GY=Grey, OR=Orange, RD=Red, YL=Yellow	

Category 6 UTP System Leads (Solid)	
MID Part Number	Description
64512299-10	SYSTEM LEAD, Category 6, RJ45, short fin boot, 10m
64512299-20	SYSTEM LEAD, Category 6, RJ45, short fin boot, 20m
64512299-30	SYSTEM LEAD, Category 6, RJ45, short fin boot, 30m
64512299-40	SYSTEM LEAD, Category 6, RJ45, short fin boot, 40m
64512299-50	SYSTEM LEAD, Category 6, RJ45, short fin boot, 50m
64512299-60	SYSTEM LEAD, Category 6, RJ45, short fin boot, 60m

[Back to contents page](#)

Complementary Copper Solutions



SL Series Termination Tool



KRONE Connection Tool with Sensor



Jacknack Cable Stripping Tool

Copper Tools	
MID Part Number	Description
1725150-6	SL Series Termination Tool - Includes Lacing Fixture
1673956-6	Lacing Fixture replacement for SL Series Termination Tool
64172055-11	LSA-PLUS® Insertion Tool with Sensor
2119000-1	Jacknack Cable Stripping Tool

* KRONE Connection Tool with Sensor (MID Part number 64172055-01) is available while stock lasts. Its replacement product is LSA-PLUS® Insertion Tool with Sensor (MID Part number 64172055-11)



IRU Cable Manager Panel with Cover



IRU 4 Ring Metal Patch Cord Minder



IRU Cable Manager Metal Finger Duct

Horizontal Cable Management	
MID Part Number	Description
Loop style	
760038240	1RU 4 Ring Metal Patch Cord Minder - Black - 80mm Loops. Includes cage nuts
760038257	2RU 4 Ring Metal Patch Cord Minder - Black - 80mm Loops. Includes cage nuts
Finger duct style, with cover	
1375162-1	1RU Cable Manager Panel with Cover
760072942	1RU Cable Manager Metal Finger Duct 75mm
760072959	2RU Cable Manager Metal Finger Duct 75mm



Clipsal/HPM Bezel for SL Jacks

Adaptor Bezels for SL/SLX Series Jacks	
CommScope SL/SLX Adaptor for Clipsal/HPM style face plates	
64671116-02	Adaptor Clip - White. Use to mount SL/SLX Jacks into Clipsal/ HPM Faceplate Bag of 10
64671116-00	Adapter Clip - Black. Use to mount SL/SLX Jacks into Clipsal/ HPM Faceplate Bag of 10
64671116-07SH	Adaptor Clip - White. WITH SHUTTER. Use to mount SL/SLX Jacks into Clipsal/HPM Faceplate Bag of 10

[Back to contents page](#)

Complementary Copper Solutions



Surface Mount Box, universal, one port, pro white



Surface Mount Box, universal, two ports, pro white



Surface Mount Box, universal, two ports, pro white

Surface Mount Outlets (SL/SLX Jacks Only)	
MID Part Number	Description
760248523	Surface Mount Module, 1-port, unloaded, White – (supports SL, SLX footprint Jacks as well as KJ style with adaptor.)
760248527	Surface Mount Module, 2-port, unloaded, White – (supports SL, SLX footprint Jacks as well as KJ style with adaptor.)
1933671-2	Surface Mount Module, 4-port, unloaded, Black – suit SL Jacks
1-1933671-3	Surface Mount Module, 4-port, unloaded, White – suit SL Jacks
1933674-2	Surface Mount Module, 6-port, unloaded, Black – suit SL Jacks
1-1933674-3	Surface Mount Module, 6-port, unloaded, White – suit SL Jacks
760246284	IP 67 Outdoor Outlet single gang, universal, Two Ports



12 Port Consolidation Point for SL Jacks

Consolidation Point	
MID Part Number	Description
2-1671163-1	CP 12 port SL patch panel + Cover unloaded black

[Back to contents page](#)

Complementary Copper Solutions



CCA UTP Connector Only



CCA Connector with Cat 6/ Cat 6_A cable assembly



CCA Shielded Connector Only

Ceiling Connector Assembly (CCA) UTP	
Field Terminated Plug Connector for Modified Permanent Link. CCA should be wired to T568B method to match patch cord.	
MID Part Number	Description
760234921	CCA UTP Connector Only (No Patch Cable). Use with Cat 5e/6/6 _A UTP Patch Cords Cut in Half
760235590	CCA Connector with Cat 6 _A LSZH UTP RJ45 Patch Cord. 450mm Long. White
Ceiling Connector Assembly (CCA) Shielded	
760250028	CCA Shielded Connector Only (No Patch Cable) Cat6 _A (5 pack)
The shielded ceiling connector assembly is a field terminated solution that does not require special tools to terminate and can be easily attached to a horizontal cable using a cut-off tool and pliers. Quick and reliable terminations are key to the product's features that simplify installations in the ceiling. Available with Patch Cord installed in, 0.9m, 2.1m, 4.5m, 6m, 7.5m.	



Modular Coloured Clips

Patch Cord Modular Plug Coloured Boot Clips	
Differentiate networks using coloured clips on patch cord plugs. (Note: For patch cords with modular plug)	
MID Part Number	Description
2843022-1	Modular Plug Colour Clip - Almond (Bag 50)
2843022-2	Modular Plug Colour Clip - Black (Bag 50)
2843022-3	Modular Plug Colour Clip - White (Bag 50)
2843022-4	Modular Plug Colour Clip - Grey (Bag 50)
2843022-5	Modular Plug Colour Clip - Orange (Bag 50)
2843022-6	Modular Plug Colour Clip - Blue (Bag 50)
2843022-7	Modular Plug Colour Clip - Red (Bag 50)
2843022-8	Modular Plug Colour Clip - Yellow (Bag 50)
2843022-9	Modular Plug Colour Clip - Green (Bag 50)

[Back to contents page](#)

Complementary Copper Solutions



64501107-01



64501103-10



64502157-10



64502157-20



64501105-21

HighBand Frame and Cable Management (for NETCONNECT UTP)

MID Part Number	Description
Terminate using KRONE Connection Tool (64172055-01)	
64501107-01	HighBand Frame Kit, Cat 6A 12way, 240 pairs
64501103-10	HighBand Frame Cable Management Kit
64502157-10	HighBand Frame Cable Trough, TOP
64502157-20	HighBand Frame Cable Trough, BOTTOM
HighBand Consolidation Point (for NETCONNECT UTP)	
64501105-21	HighBand Consolidation Point, Cat 6 _A 100 pair



Rear Facing Patch Cord



Front Facing Patch Cord

HighBand Patch Cords

MID Part Number	Description
Rear Facing to Rear Facing	
C01HHG2-OZM001	HighBand 4pr Rear Facing to Rear Facing Patch Cord 568B, 1m
C01HHG2-OZM002	HighBand 4pr Rear Facing to Rear Facing Patch Cord 568B, 2m
C01HHG2-OZM003	HighBand 4pr Rear Facing to Rear Facing Patch Cord 568B, 3m
C01HHG2-OZM005	HighBand 4pr Rear Facing to Rear Facing Patch Cord 568B, 5m
Front Facing to RJ45	
C01G5G2-OZF004	HighBand Front Facing to Rj45 568B, 1.2m
C01G5G2-OZF007	HighBand Front Facing to Rj45 568B, 2.1m
C01G5G2-OZF010	HighBand Front Facing to Rj45 568B, 3.0m
C01G5G2-OZF015	HighBand Front Facing to Rj45 568B, 4.5m
C01G5G2-OZF017	HighBand Front Facing to Rj45 568B, 5.0m

[Back to contents page](#)

Fibre Solutions

Fibre Optic Cables



Fibre Optic Cables - Indoor Distribution	
MID Part Number	Description
OM4 50/125um (3500/500 MHz.km) Internal Distribution Cable	
760012153	OM4 50/125µm, Internal Riser Distribution Cable, OD 6mm, ULSZH, 6 core fibre
760012161	OM4 50/125µm, Internal Riser Distribution Cable, OD 7.5mm, ULSZH, 12 core fibre
760019117	OM4 50/125µm, Internal Riser Distribution Cable, OD 9.5mm, ULSZH, 24 core fibre
OS2 9/125um Internal Distribution Cable	
760004242	OS2 9/125µm, Internal Riser Distribution Cable, OD 6mm, ULSZH, 6 core fibre
760004267	OS2 9/125µm, Internal Riser Distribution Cable, OD 7.5mm, ULSZH, 12 core fibre
760019075	OS2 9/125µm, Internal Riser Distribution Cable, OD 9.5mm, ULSZH, 24 core fibre

Other cables available on request



Fibre Optic Cables - Outdoor/Underground	
Designed for external underground installations in (micro) ducts by pulling, blowing or floating techniques. Polyamide provides anti-termite protection. Optimised for blowing in mini ducts of 10mm diameter (internal).	
MID Part Number	Description
OM4 50/125um Mini Loose Tube (3500/500 MHz.km) External Optical Cable	
64624474-06MLT	6 Core OM4 50/125µm, Gel-filled Loose Tube Cable, OD 6.3mm
64624474-12MLT	12 Core OM4 50/125µm, Gel-filled Loose Tube Cable, OD 6.3mm
64624474-24MLT	24 Core OM4 50/125µm, Gel-filled Loose Tube Cable, OD 6.3mm
64624474-48MLT	48 Core OM4 50/125µm, Gel-filled Loose Tube Cable, OD 6.3mm
64624474-72MLT	72 Core OM4 50/125µm, Gel-filled Loose Tube Cable, OD 6.3mm
64624474-144MLT	144 Core OM4 50/125µm, Gel-filled Loose Tube Cable, OD 8.4mm
OS2 9/125um Mini Loose Tube External Optical Cable	
64623447-12MLT	12 Core SM CSM External Mini Loose Tube OD 6.3mm
64623447-24MLT	24 Core SM CSM External Mini Loose Tube OD 6.3mm
64623447-48MLT	48 Core SM CSM External Mini Loose Tube OD 6.3mm
64623447-72MLT	72 Core SM CSM External Mini Loose Tube OD 6.3mm
64623447-144MLT	144 Core SM CSM External Mini Loose Tube OD 8.4mm

Other cables available on request

[Back to contents page](#)

Fibre Solutions

Fibre Connectivity - Splice



1RU FMS Tray OM4 – (up to 48f in LC)

1RU FMS Tray OS2 – (up to 48f in LC)

FMS Solution - Rackmount Fibre Trays - 19" (Fully Loaded)

OM4 Fully Loaded Sliding Fibre Tray - (includes adaptors, coloured pigtails, splice tray, splice sleeves & cable glands.)

MID Part Number	Description	Mode	Ports	Adapt
760254441	1RU FMS Tray, 12 port OM4 LC (6 x LC Duplex)	OM4	12	LC
760254442	1RU FMS Tray, 24 port OM4 LC (12 x LC Duplex)	OM4	24	LC
760254443	1RU FMS Tray, 48 port OM4 LC (24 x LC Duplex)	OM4	48	LC
760254439	1RU FMS Tray, 12 port OM4 SC (6 x SC Duplex)	OM4	12	SC
760254440	1RU FMS Tray, 24 port OM4 SC (12 x SC Duplex)	OM4	24	SC

OS2 Fully Loaded Sliding Fibre Tray - (includes adaptors, coloured pigtails, splice tray, splice sleeves & cable glands.)

MID Part Number	Description	Mode	Ports	Adapt
760254436	1RU FMS Tray, 12 port OS2 LC (6 x LC Duplex)	OS2	12	LC
760254437	1RU FMS Tray, 24 port OS2 LC (12 x LC Duplex)	OS2	24	LC
760254438	1RU FMS Tray, 48 port OS2 LC (24 x LC Duplex)	OS2	48	LC
760254122	1RU FMS Tray, 12 port OS2 SC (6 x SC Duplex)	OS2	12	SC
760254435	1RU FMS Tray, 24 port OS2 SC (12 x SC Duplex)	OS2	24	SC



760249998



760251044



760242476

EPX Solution - Rackmount Fibre Trays - 19" (Configurable)

Fixed and Sliding Drawers

MID Part Number	Description
These enclosures are best suited for splice solutions. (Refer Page 22 for Adaptor Packs, Page 23 for Adaptor Cassettes incl. splicing)	
760249998	1U Sliding Drawer Panel, accepts (4) G2 modules or adapter packs, up to 48 DPX LC or 32 MPO ports
760251044	2U Sliding Drawer Panel, accepts (8) G2 modules or adapter packs, up to 96 DPX LC or 64 MPO ports
760251048	4U Sliding Drawer Panel, accepts (16) G2 modules or adapter packs, up to 192 DPX LC or 128 MPO ports

AGILE Tray

760242476	AGILE 1U enclosed sliding panel, accepts (4) G2 modules providing up to 48 duplex LC or 32 MPO ports
-----------	--

[Back to contents page](#)

Fibre Solutions

Fibre Connectivity - Splice



SC Singlemode



SC OM4



LC Singlemode



LC OM4

AGILE G2 Connectorised Adaptor Packs

MID Part Number	Description
Singlemode	
760135087	G2 Singlemode Distribution Adapter Pack 12F SC Blue
760230946	G2 Singlemode Distribution Adapter Pack 12F LC Blue
760216762	G2 Singlemode Distribution Adapter Pack 24F LC Blue
760135095	G2 Singlemode Distribution Adapter Pack 12F SC APC Green
760230961	G2 Singlemode Distribution Adapter Pack 12F LC APC Green
760216770	G2 Singlemode Distribution Adapter Pack 24F LC APC Green
Multimode	
760134551	G2 Multimode Distribution Adapter Pack 12F SC Aqua
760230938	G2 Multimode Distribution Adapter Pack 12F LC OM4 Aqua
760216754	G2 Multimode Distribution Adapter Pack 24F LC OM4 Aqua
760109462	G2 Mod Panel Blank Adapter Pack, 4 Panels
Refer Page 23 for Connectorised Cassette options (fully enclosed cassette with splice trays and Pigtails)	



G2 Splice Tray



Patch Cable Gland Kit



Trunk Cable Gland Kit



Quick-Fit to G2 Adaptor



Splice Protector


G2 Accessories

MID Part Number	Description
760241378	Fiber Optic Splice Tray Kit, stackable, 48-fiber capacity (splice protectors included)
760109462	G2 Mod Panel Blank Adapter Pack, 4 Panels
760242678	Patch cord fitting kit with 12 cable glands
760242679	Trunk cable fitting kit with 12 cable glands
760242369	UCP/Quick-Fit to G2 Adapter Bracket Kit (kit of 4)
103897-000	Splice Protector, 45mm SMOUV (Bag of 100)
369305-000	Splice Protector, 62mm SMOUV (Bag of 100)

[Back to contents page](#)

Fibre Solutions

Fibre Connectivity - Splice

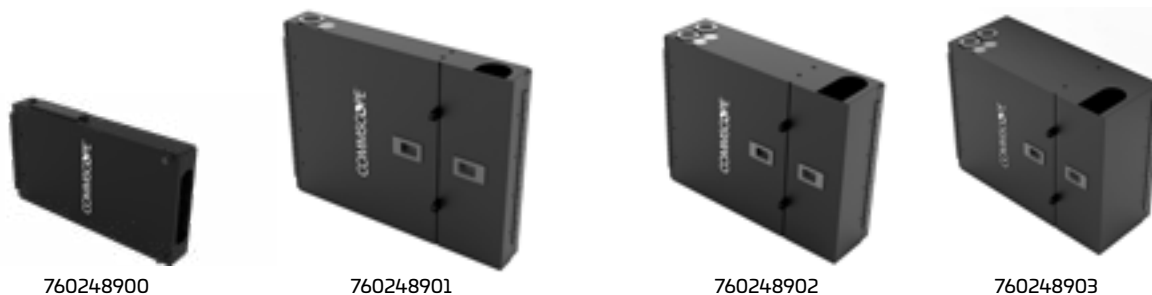

760248900

760248901

760248902

760248903

AGILE G2 Solution – Wall Mount Fibre Enclosures

Accept G2 style 12 and 24F adaptor packs

MID Part Number	Description
-----------------	-------------

These enclosures are best suited for splice solutions

760248900	Wall Mount Enclosure, accepts one G2 LC splice cassette 12/24F
760248901	Wall Mount Enclosure, accepts two G2 LC splice cassettes 24/48F
760248902	Wall Mount Enclosure, accepts four G2 LC splice cassettes 48/96F
760248903	Wall Mount Enclosure, accepts eight G2 LC splice cassettes 96/192F



760245399

760244929

AGILE G2 Solution – Wall Mount Adaptor/Splice Cassette

Internal Shutter with Pigtails

MID Part Number	Description
-----------------	-------------

OM4 LC

760244927	G2 Splice Cassette, 24LC with internal shutters, OM4, with pigtails
760245399	G2 Splice Cassette, 12LC with internal shutters, OM4, with pigtails

OS2 LC

760244929	G2 Splice Cassette, 24LC/UPC with internal shutters, OS2, with pigtails
760245401	G2 Splice Cassette, 12LC/UPC with internal shutters, OS2, with pigtails

[Back to contents page](#)

Fibre Solutions

Fibre Connectivity - Splice Solutions



Pigtail 1.5 metre Pack of 12

Fibre Optic Pigtails	
MID Part Number	Description
OM4 Pigtails, 50/125µm, 1 Fibre, 900um, 1.5mtr, LSZH Tight Buffered Fibre	
FAXLCUCOA-XXF005	LC Pigtails, OM4, 1F, 1.5mtr - Pkt of 6 - Colour Coded
FAXLCUCOC-XXF005	LC Pigtails, OM4, 1F, 1.5mtr - Pkt of 12 - Colour Coded
FAXSCUCOA-XXF005	SC Pigtails, OM4, 1F, 0.9mm, 1.5mtr - Pkt of 6
FAXSCUCOC-XXF005	SC Pigtails, OM4, 1F, 0.9mm, 1.5mtr - Pkt of 12
OS2 Pigtails, 9/125µm, 1 Fibre, 900um, 1.5mtr, LSZH Tight Buffered Fibre	
FAWLCUCOA-XXF005	LC Pigtails, OS2, 1F, 0.9mm, 1.5m - Pkt of 6
FAWLCUCOC-XXF005	LC Pigtails, OS2, 1F, 0.9mm, 1.5m - Pkt of 12
FAWSCUCOA-XXF005	SC Pigtails, OS2, 1F, 0.9mm, 1.5mtr - Pkt of 6 - Colour Coded
FAWSCUCOC-XXF005	SC Pigtails, OS2, 1F, 0.9mm, 1.5mtr - Pkt of 12 - Colour Coded
OS2 Pigtails, 9/125µm, 1 Fibre, 900um, 1.5mtr, LSZH Tight Buffered Fibre	
CY3922-000	Pigtail, A1, LCA, 1F, 1.5m Long, 900 Micron, Pkt of 12 Colour Coded
CZ6937-000	Pigtail, A1, SCA, 1F, 1.5m Long, 900 Micron, Pkt of 12 Colour Coded



Fiber Optic Duplex Adapter Flanges



Fiber Optic Duplex Adapter Flangeless



TeraSPEED®



LazrSPEED®

Fibre Connectors	
MID Part Number	Description
EH1457-002	Fiber Optic Duplex Adapter, Multimode LC/UPC, Aqua, with flanges
CP7685-000	Fiber Optic Duplex Adapter, Singlemode LC/UPC, blue, flangeless
760034199	TeraSPEED® Behind The Wall Pre-Radiused LC Connector for 0.9mm Fiber, Singlemode
760034181	LazrSPEED® Behind The Wall Pre-Radiused LC Connector for 0.9 mm Fiber, Multimode

[Back to contents page](#)

Fibre Solutions

Fibre Connectivity - MPO*



760241517



760241518



760254918

EPX G2 Rackmount Fibre Trays - 19"

MID Part Number	Description
Fixed and Sliding Panels	
These enclosures are best suited for MPO* solutions	
760241517	EPX 1U fixed panel, accepts (4) G2 modules or adapter packs providing up to 48 duplex LC or 32 MPO ports
760241518	EPX 1U fixed angled panel, accepts (4) G2 modules or adapter packs providing up to 48 duplex LC or 32 MPO ports
760254918	EPX 1U open sliding panel, accepts (4) G2 style splice cassettes, modules or adapter packs, providing up to 48 duplex LC ports. This will match the EPX Panels with the front Cable manager.



MPO Singlemode



MPO-12 OM4, 1x12f MPO port



MPO-24 OM4, 2x12f MPO ports



G2 MPO* Adapter Modules

G2 Modules MPO-LC - OM4, for 12 Fibre MPO cables, use with AGILE G2 Panels and Drawers

MID Part Number	Description
Modules work with 12 fibre MPO Cables. Not compatible with 24 Fibre MPO Cables	
760242493	G2 MPOOptimate® MPO-12 Distribution Module, 1x12F MPO pinned to 12F LC, Method A Pair Straight OM4, Aqua
760242494	G2 MPOOptimate® MPO-12 Distribution Module, 1x12F MPO pinned to 12F LC, Method A Pair Flipped OM4, Aqua
760242495	G2 MPOOptimate® MPO-12 Distribution Module, 2x12F MPO pinned to 24F LC, Method A Pair Straight OM4, Aqua
760242496	G2 MPOOptimate® MPO-12 Distribution Module, 2x12F MPO pinned to 24F LC, Method A Pair Flipped OM4, Aqua

G2 Modules MPO-LC - OS2, for 12 Fibre MPO cables, use with G2 Panels and Drawers

760242498	G2 MPO-12 Distribution Module, 1x12F MPO pinned to 12F LC, Method A Pair Straight Singlemode, Blue
760242499	G2 MPO-12 Distribution Module, 1x12F MPO pinned to 12F LC, Method A Pair Flipped Singlemode, Blue
760242500	G2 MPO-12 Distribution Module, 2x12F MPO pinned to 24F LC, Method A Pair Straight Singlemode, Blue
760242501	G2 MPO-12 Distribution Module, 2x12F MPO pinned to 24F LC, Method A Pair Flipped Singlemode, Blue

G2 Modules, MPO-MPO, use with G2 Panels and Drawers

760242723	G2 Distribution Adapter Pack, 6 x MPO, Method A
760242724	G2 Distribution Adapter Pack, 8 x MPO, Method A

* CommScope's MPO solution complies with IEC 61754-7 MPO Connector Family. MTP componentry may be used in the connector.

[Back to contents page](#)

Fibre Solutions

Fibre Patch Cords



Patch Cord OM4 LC-LC



Patch Cord OS2 LC LC

Fibre Optic Patch Cords UPC	
MID Part Number	Description
OM4, LC-LC 2 FIBRE 1.8MM AQUA CORD - LSZH	
FFXLCLC42-MXM001	Patchcord, OM4, LC, 2F, 1.0m
FFXLCLC42-MXM002	Patchcord, OM4, LC, 2F, 2.0m
FFXLCLC42-MXM003	Patchcord, OM4, LC, 2F, 3.0m
FFXLCLC42-MXM005	Patchcord, OM4, LC, 2F, 5.0m
FFXLCLC42-MXM010	Patchcord, OM4, LC, 2F, 10.0m
OM4, SC-SC 2 FIBRE 1.8MM AQUA CORD - LSZH	
FFXSCSC42-MXM001	Patchcord, OM4, SC, 2F, 1.0m
FFXSCSC42-MXM002	Patchcord, OM4, SC, 2F, 2.0m
FFXSCSC42-MXM003	Patchcord, OM4, SC, 2F, 3.0m
FFXSCSC42-MXM005	Patchcord, OM4, SC, 2F, 5.0m
FFXSCSC42-MXM010	Patchcord, OM4, SC, 2F, 10.0m
OS2, LC-LC 2 FIBRE 1.8MM YELLOW CORD - LSZH	
FFWLCLC42-JXM001	Patchcord, OS2, LC, 2F, 1.0m
FFWLCLC42-JXM002	Patchcord, OS2, LC, 2F, 2.0m
FFWLCLC42-JXM003	Patchcord, OS2, LC, 2F, 3.0m
FFWLCLC42-JXM005	Patchcord, OS2, LC, 2F, 5.0m
FFWLCLC42-JXM010	Patchcord, OS2, LC, 2F, 10.0m
OS2, SC-SC 2 FIBRE 1.8MM YELLOW CORD - LSZH	
FFWSCSC42-JXM001	Patchcord, OS2, SC, 2F, 1.0m
FFWSCSC42-JXM002	Patchcord, OS2, SC, 2F, 2.0m
FFWSCSC42-JXM003	Patchcord, OS2, SC, 2F, 3.0m
FFWSCSC42-JXM005	Patchcord, OS2, SC, 2F, 5.0m
FFWSCSC42-JXM010	Patchcord, OS2, SC, 2F, 10.0m
Other Patch Cords available on request.	

[Back to contents page](#)

Fibre Solutions

Fibre Patch Cords



OS2 SCA-SCA



OS2 LCA-LCA

Fibre Optic Patch Cords APC	
MID Part Number	Description
Patchcord Singlemode 9/125µm - LC/ANGLED 2 FIBRE 1.6MM YELLOW CORD – RISER/PVC	
FEWLALA42-JXM001	Patchcord, OS2, LCA, 2F, 1.0m
FEWLALA42-JXM002	Patchcord, OS2, LCA, 2F, 2.0m
FEWLALA42-JXM003	Patchcord, OS2, LCA, 2F, 3.0m
FEWLALA42-JXM005	Patchcord, OS2, LCA, 2F, 5.0m
FEWLALA42-JXM010	Patchcord, OS2, LCA, 2F, 10.0m
Patchcord Singlemode 9/125 - SC/ANGLED 2 FIBRE 1.6MM YELLOW CORD - RISER/PVC	
FEWSASA42-JXM001	Patchcord, OS2, SCA, 2F, 1.0m
FEWSASA42-JXM002	Patchcord, OS2, SCA, 2F, 2.0m
FEWSASA42-JXM003	Patchcord, OS2, SCA, 2F, 3.0m
FEWSASA42-JXM005	Patchcord, OS2, SCA, 2F, 5.0m
FEWSASA42-JXM010	Patchcord, OS2, SCA, 2F, 10.0m
Other Patch Cords available on request.	

[Back to contents page](#)

Fibre Solutions

Fibre Patch Cords



MPO to MPO OM4 Patch Cable



MPO to MPO OM4 Trunk Cable

MPO* Patch Cable, 3.2mm OSD, LSZH, OM4, 12 Fibre - Straight

MPO Patch cables are best suited for Data Centre environments or installed on dedicated pathways (FiberGuide)

MID Part Number	Description
ARXMPMPGD-MAM005	MPO to MPO Patch Cable OM4 12 Fibre LSZH, Indoor Straight - 5mtr
ARXMPMPGD-MAM010	MPO to MPO Patch Cable OM4 12 Fibre LSZH, Indoor Straight - 10mtr
ARXMPMPGD-MAM015	MPO to MPO Patch Cable OM4 12 Fibre LSZH, Indoor Straight - 15mtr
ARXMPMPGD-MAM020	MPO to MPO Patch Cable OM4 12 Fibre LSZH, Indoor Straight - 20mtr
ARXMPMPGD-MAM025	MPO to MPO Patch Cable OM4 12 Fibre LSZH, Indoor Straight - 25mtr
ARXMPMPGD-MAM030	MPO to MPO Patch Cable OM4 12 Fibre LSZH, Indoor Straight - 30mtr

Lengths 35-50 meters available on request.

MPO* Trunk Cable, 6.4mm OSD, LSZH, OM4, 12 Fibre - Straight

Trunk cables best suited for Backbone cabling on common pathways

MID Part Number	Description
AJXMPMPAD-MAM010	MPO to MPO Trunk OM4 12 Fibre LSZH, indoor Straight 10mtr
AJXMPMPAD-MAM015	MPO to MPO Trunk OM4 12 Fibre LSZH, indoor Straight 15mtr
AJXMPMPAD-MAM020	MPO to MPO Trunk OM4 12 Fibre LSZH, indoor Straight 20mtr
AJXMPMPAD-MAM025	MPO to MPO Trunk OM4 12 Fibre LSZH, indoor Straight 25mtr
AJXMPMPAD-MAM030	MPO to MPO Trunk OM4 12 Fibre LSZH, indoor Straight 30mtr
AJXMPMPAD-MAM035	MPO to MPO Trunk OM4 12 Fibre LSZH, indoor Straight 35mtr
AJXMPMPAD-MAM040	MPO to MPO Trunk OM4 12 Fibre LSZH, indoor Straight 40mtr
AJXMPMPAD-MAM045	MPO to MPO Trunk OM4 12 Fibre LSZH, indoor Straight 45mtr
AJXMPMPAD-MAM050	MPO to MPO Trunk OM4 12 Fibre LSZH, indoor Straight 50mtr
AJXMPMPAD-MAM060	MPO to MPO Trunk OM4 12 Fibre LSZH, indoor Straight 60mtr
AJXMPMPAD-MAM070	MPO to MPO Trunk OM4 12 Fibre LSZH, indoor Straight 70mtr
AJXMPMPAD-MAM080	MPO to MPO Trunk OM4 12 Fibre LSZH, indoor Straight 80mtr
AJXMPMPAD-MAM090	MPO to MPO Trunk OM4 12 Fibre LSZH, indoor Straight 90mtr
AJXMPMPAD-MAM100	MPO to MPO Trunk OM4 12 Fibre LSZH, indoor Straight 100mtr

Length available up to 300m on request

*CommScope's MPO solution complies with IEC 61754-7 MPO Connector Family. MTP componentry may be used in the multi-fibre connector.

[Back to contents page](#)

Fibre Solutions

Fibre Patch Cords



MPO to MPO OS2 Patch Cable



MPO to MPO OS2 Trunk Cable

MPO* Patch Cable, 3.2mm OSD, LSZH, OS2, 12 Fibre - Straight

MPO Patch cables are best suited for Data Centre environments or installed on dedicated pathways (FiberGuide)

MID Part Number	Description
ARGMPMPGD-JAM005	MPO to MPO Patch Cable, OS2, 12 Fibre (straight), Yellow - 5mtr
ARGMPMPGD-JAM010	MPO to MPO Patch Cable, OS2, 12 Fibre (straight), Yellow - 10mtr
ARGMPMPGD-JAM015	MPO to MPO Patch Cable, OS2, 12 Fibre (straight), Yellow - 15mtr
ARGMPMPGD-JAM020	MPO to MPO Patch Cable, OS2, 12 Fibre (straight), Yellow - 20mtr
ARGMPMPGD-JAM025	MPO to MPO Patch Cable, OS2, 12 Fibre (straight), Yellow - 25mtr
ARGMPMPGD-JAM030	MPO to MPO Patch Cable, OS2, 12 Fibre (straight), Yellow - 30mtr

Lengths 35-50 meters available on request.

MPO* Trunk Cable, 6.4mm OSD, LSZH, OS2, 12 Fibre - Straight

Trunk cables best suited for Backbone cabling on common pathways

AJGMPMPAD-JAM010	MPO to MPO Trunk Cable, OS2 SM, LSZH, 12 Fibre, 10mtr
AJGMPMPAD-JAM015	MPO to MPO Trunk Cable, OS2 SM, LSZH, 12 Fibre, 15mtr
AJGMPMPAD-JAM020	MPO to MPO Trunk Cable, OS2 SM, LSZH, 12 Fibre, 20mtr
AJGMPMPAD-JAM025	MPO to MPO Trunk Cable, OS2 SM, LSZH, 12 Fibre, 25mtr
AJGMPMPAD-JAM030	MPO to MPO Trunk Cable, OS2 SM, LSZH, 12 Fibre, 30mtr
AJGMPMPAD-JAM035	MPO to MPO Trunk Cable, OS2 SM, LSZH, 12 Fibre, 35mtr
AJGMPMPAD-JAM040	MPO to MPO Trunk Cable, OS2 SM, LSZH, 12 Fibre, 40mtr
AJGMPMPAD-JAM045	MPO to MPO Trunk Cable, OS2 SM, LSZH, 12 Fibre, 45mtr
AJGMPMPAD-JAM050	MPO to MPO Trunk Cable, OS2 SM, LSZH, 12 Fibre, 50mtr
AJGMPMPAD-JAM060	MPO to MPO Trunk Cable, OS2 SM, LSZH, 12 Fibre, 60mtr
AJGMPMPAD-JAM070	MPO to MPO Trunk Cable, OS2 SM, LSZH, 12 Fibre, 70mtr
AJGMPMPAD-JAM080	MPO to MPO Trunk Cable, OS2 SM, LSZH, 12 Fibre, 80mtr
AJGMPMPAD-JAM090	MPO to MPO Trunk Cable, OS2 SM, LSZH, 12 Fibre, 90mtr
AJGMPMPAD-JAM100	MPO to MPO Trunk Cable, OS2 SM, LSZH, 12 Fibre, 100mtr

Lengths available up to 300m on request

*CommScope's MPO solution complies with IEC 61754-7 MPO Connector Family. MTP componentry may be used in the multi-fibre connector.

[Back to contents page](#)

Fibre Solutions

Fibre Accessories



SC/ LC One-Click Cleaner



MPO Cleaner

Fibre Optic Cleaning Accessories	
MID Part Number	Description
2064500-1	LC One-Click Cleaner for Fibre Adaptors. Cleans over 500 connectors
2064499-1	SC One-Click Cleaner for Fibre Adaptors. Cleans over 500 connectors
1152057-6	MPO One-Click Cleaner for Fibre Bulkheads. Cleans over 500 connectors



Patch Cable Gland Kit



Trunk Cable Gland Kit




Quick-Fit to G2 Adaptor



G2 Panel Blank Adaptor (4 pack)

Fibre Panel Accessories	
MID Part Number	Description
760242678	Patch cord fitting kit with 12 cable glands
760242679	Trunk fitting kit with 12 cable glands
760242369	UCP/Quick-Fit to G2 Adapter Bracket Kit (kit of 4)
760109462	G2 Mod Panel Blank Adapter Pack, 4 Panels

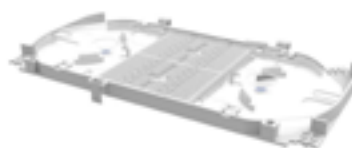

G2 Splice Tray



Splice Protector

Fibre Splicing Accessories	
MID Part Number	Description
760241378	Fiber Optic Splice Tray Kit, stackable, 48-fiber capacity
103897-000	Splice Protector, 45mm SMOUV (Bag of 100)
369305-000	Splice Protector, 62mm SMOUV (Bag of 100)

[Back to contents page](#)

Fibre Solutions

Fibre Accessories

POWERED FIBER CABLE SYSTEM

- Outdoor and riser/LSZH, indoor/outdoor rated versions
- SELV and NEC Class 2 compliant
- Fast “banana peel” style cable access
- Utilizes globally existing, proven and inexpensive FTTH-style flat cable hardware



PFU-P-E-O-060-01



PFU-P-C-O-060-02

1 And 2-Port POE Extenders

MID Part Number	Description
PFU-P-E-O-060-01	60W, 1 Port 5 Gbps PoE Extender
PFU-P-C-O-060-02	60W, 2 Port PoE Extender*

*The 60W, 2-port PoE Extender provides a maximum of 30W on each port.

- IP68 sealing—Enclosures are designed for outdoor installations with protection from moisture and the environment
- Automatically corrects for distance voltage drop in the hybrid cable
- Integrated Electrical Protection
- 60W 2-port variant enables 2 PoE or PoE+ devices to be connected via one hybrid cable
- 60W single port variation supports 802.3bt, Class 6 power levels. It can be equipped with SPF+ transceivers, and deliver 5 Gbps Ethernet over the copper port



Powered Fibre Cable

Powered Fibre Cable

MID Part Number	Description
PFC-S02012	Powered Fibre Cable, OS2, 2 Fibres, Outdoor, 12AWG Conductor
PFC-S04012	Powered Fibre Cable, OS2, 4 Fibres, Outdoor, 12AWG Conductor
PFC-S12012	Powered Fibre Cable, OS2, 12 Fibres, Outdoor, 12AWG Conductor

[Back to contents page](#)

CommScope pushes the boundaries of communications technology with game-changing ideas and ground-breaking discoveries that spark profound human achievement. We collaborate with our customers and partners to design, create and build the world's most advanced networks. It is our passion and commitment to identify the next opportunity and realize a better tomorrow. Discover more at commscope.com

CUSTOMER SERVICE

Phone: 1800 801 298 (Option 1)
Email: customerservice.au@commscope.com

TECHNICAL ASSISTANCE

Phone: 1800 801 298 (Option 2)
www.commscope.com/support-tac
Log request online <https://extapps.commscope.com/supportcenter/>

OFFICE LOCATIONS

SYDNEY
Level 1
10a Julius Avenue
North Ryde, New South Wales 2113

MELBOURNE
Level 1, 315 Ferntree Gully Road
Mount Waverley, Victoria 3149

BRISBANE
436/ Level 4
Jubilee Place
470 St Pauls Terrace
Fortitude Valley, QLD, 4007

COMMSCOPE®

commscope.com

Visit our website or contact your local CommScope representative for more information.

© 2023 CommScope, Inc. All rights reserved.

CommScope and the CommScope logo are registered trademarks of CommScope and/or its affiliates in the U.S. and other countries. For additional trademark information see <https://www.commscope.com/trademarks>. All product names, trademarks and registered trademarks are property of their respective owners.

CO-113381-EN (10/23)