

SEC3-B5A1H1CA000



NOVUX™ SEC Closure, splice only, ANT splice holder, no adapters, no splitters, mounting included, black

- Design optimized for FTTH façade applications with gray and black colors
- Agnostic to connectivity technologies: splice, connector, field-installable connector for agility and flexibility
- Innovative removable hinge design allows cover to open from the left, right, or top
- Identification plate for either QR code or customer logo
- QR code and CommScope cTrak® app for one-click access to all product information

Product Classification

Regional Availability	EMEA
Regional Availability Note	Contact your local CommScope representative for specific availability
Product Type	In-line, rectangular fiber closure
Product Brand	NOVUX™
Product Series	SEC100

General Specifications

Cable Capacity, Branch	2 Round 8.0–12.0 mm (0.31–0.47 in)
Cable Capacity, Drop	6 Round 3.0–6.0 mm (0.12–0.23 in) for pre-connectorized cables 6 Round 3.0–7.0 mm (0.12–0.27 in)
Cable Capacity, Feeder	2 Round 8.0–12.0 mm (0.31–0.47 in)
Cable Ports Quantity, total	10 round ports
Cable Sealing Type	Gasket/grommet configuration
Closure Sealing Type	Hinged with lock
Closure Style	In-line
Color	Black
Mounting	Facade Wall
Network Area Type	Drop
Port Type	No adapter No adapter
Splice Tray Included, quantity	1
Splices per Tray, quantity	18
Splicing Capacity, maximum	54
Splicing Capacity, Single Fusion, maximum	54

SEC3-B5A1H1CA000

Splicing Type, Supported Single fusion

Splitter Type No splitter

Splitter, quantity 0

Dimensions


Height 130 mm | 5.118 in

Width 216 mm | 8.504 in

Depth 87 mm | 3.425 in

Ordering Tree

Ordering information

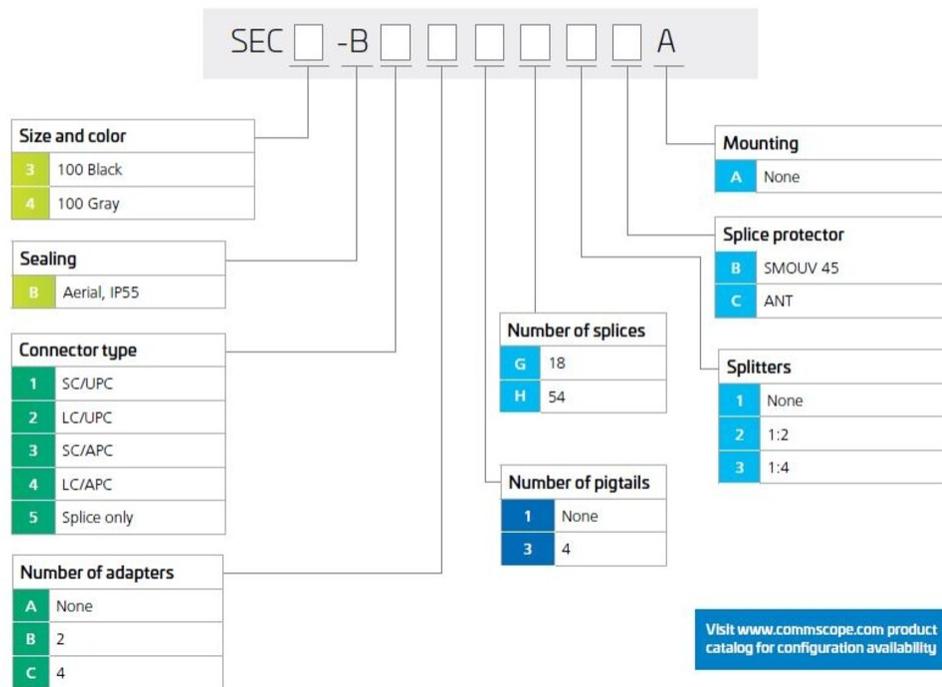

Optical Specifications

Fiber Type G.657.A1 | G.657.A2 | G.657.B3

Environmental Specifications

Environmental Space Facade | Outdoor

Qualification Standards IP55

UV Resistance UV stabilized

SEC3-B5A1H1CA000

Packaging and Weights

Packaging quantity	1
Packaging Type	Box Carton