


MP-PP15M-15C-96

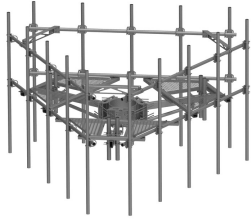

PIM Optimized Adjustable Monopole Platform with 15ft Face - 2-7/8in OD Face Pipes & Top Rail - Includes (15) 2-7/8in OD x 96in Antenna Pipes

Product Classification

Product Type	Co-location platform
Product Brand	PIM-guard

General Specifications

Mounting	Monopole, 304.8–1143 mm (12–45 in) OD
Pipe, quantity	15
Sectors, quantity	3

Dimensions

Height	2,438.4 mm 96 in
Face Width	4,572 mm 15 ft
Width	4,572 mm 180 in
Pipe Length	2,438.4 mm 96 in
Face Support Pipe Diameter	73.152 mm 2.88 in
Mounting Diameter, maximum	1,143 mm 45 in
Mounting Diameter, minimum	304.8 mm 12 in
Pipe Outer Diameter	73.152 mm 2.88 in

Material Specifications

Material Type	Hot dip galvanized steel
----------------------	--------------------------

Mechanical Specifications

Wind Rating Test Method	TIA/EIA-222
--------------------------------	-------------

Packaging and Weights

Included	Plain end pipes Platform Rail Ring mount
Packaging quantity	1

MP-PP15M-15C-96

Weight, net

1,369.123 kg | 3,018.4 lb

