


# MCG23RHDXL-15MB

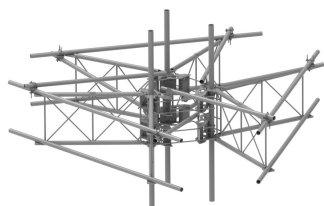

G23RHDXL PIM OPTIMIZED SPACING High Capacity Monopole platform with extended 10' Spine for RRU Mounting & extended frame for sites requiring increased sector to sector antenna spacing. 2 7/8in OD x 15ft face. Antenna pipes sold separately.

- Extended spine for MCG23 RHDXL mounts that decrease PIM from radio relocation PLUS extended frames for increased antenna-to-antenna spacing
- Increased versatility and stability
- Updated frame provides higher loading
- More RRU mounting available, reducing need for additional mounts
- Better load management
- Less structure stress
- Designed to be used in combination with APEX RRU mounts

## Product Classification

Product Type	High capacity monopole sector frame
Product Brand	PIM-guard
Product Series	G2

## General Specifications

Mounting	Monopole, 381–1270 mm (15–50 in) OD
Pipe, quantity	0
Sectors, quantity	3

## Dimensions

Height	3,048 mm   120 in
Face Width	4,572 m   15 ft
Width	4,572 mm   180 in
Face Support Pipe Diameter	73.025 mm   2.875 in
Mounting Diameter, maximum	1270 mm   50 in
Mounting Diameter, minimum	381 mm   15 in
Pipe Outer Diameter	73.025 mm   2.875 in
Stand-off Distance	1,549.4 mm   61 in

## Material Specifications

Material Type	Hot dip galvanized steel
---------------	--------------------------

# MCG23RHDXL-15MB

---

## Mechanical Specifications

Wind Rating	For Specifications, please contact your local ANDREW representative
Wind Rating Test Method	TIA/EIA-222

## Packaging and Weights

Included	Mounting hardware   Ring mounts (2)   Sector frames (3)   Stiff arm
Packaging quantity	1
Weight, net	1,110.848 kg   2449 lb

## \* Footnotes

Wind Rating	BWS—Base Wind Speed; FBC—Florida Building Code
-------------	--