


ULGQXQXBF

Base Product

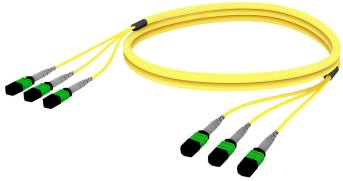

Ultra Low Loss (ULL) Singlemode MPO8 (Pinned) to MPO8 (Pinned), Ruggedized fanout Cable, 24-Fiber, Plenum

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Ruggedized fanout
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Gray
Color, connector A	Green
Color, boot B	Gray
Color, connector B	Green
Construction Type	Stranded
Furcation Color	Yellow
Interface, Connector A	MPO-08/APC Male
Interface Feature, connector A	QSFP configuration
Interface, Connector B	MPO-08/APC Male
Interface Feature, connector B	QSFP configuration
Jacket Color	Yellow
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	24


Dimensions

Breakout Length	33 in
------------------------	-------

ULGQXQXBF

Cable Assembly Length Range (m) 3 – 999
Cable Assembly Length Range (ft) 10 – 999

Ordering Tree

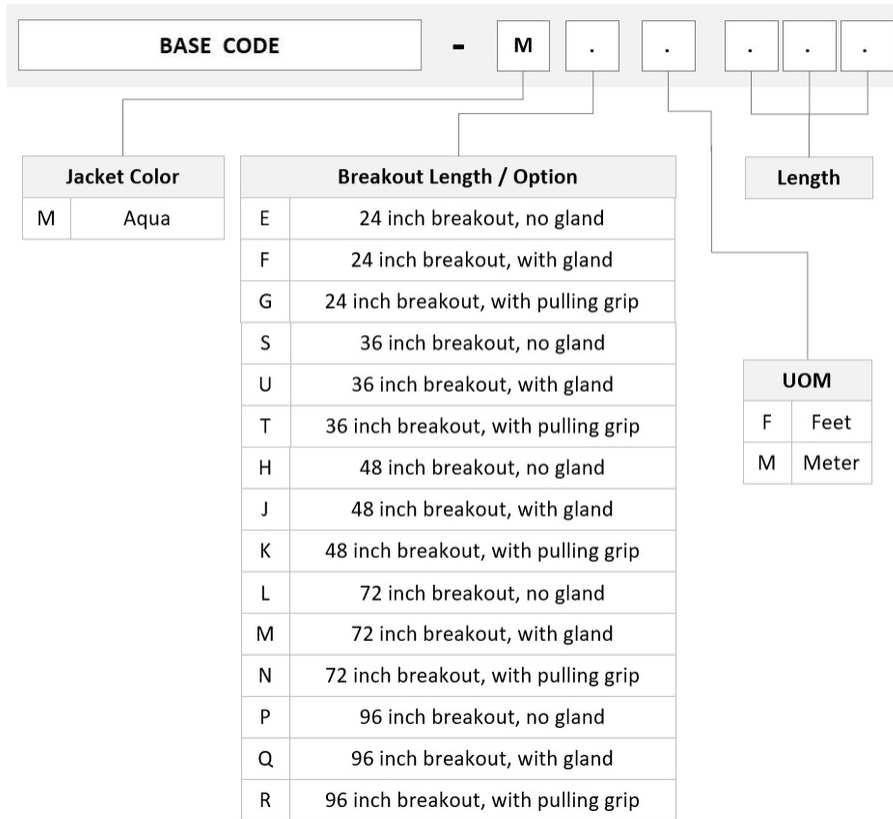

Mechanical Specifications

Cable Retention Strength, maximum 11.24 lb @ 0° | 4.40 lb @ 90°

Optical Specifications

Fiber Mode Singlemode
Fiber Type G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space Plenum

ULGQXQXBF

Regulatory Compliance/Certifications

Agency

ANATEL

ISO 9001:2015

Classification

Compliant

Designed, manufactured and/or distributed under this quality management system



Included Products

760260235

P-024-MP-8G1-F24YL/30T

860637705

- Fiber indoor cable, Plenum MPO Trunk Cable, 24 fiber with 24-fiber, 3.0mm subunit, Gel-free, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color
- MPO8, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 3mm