


# UNGQXQXBF

Base Product

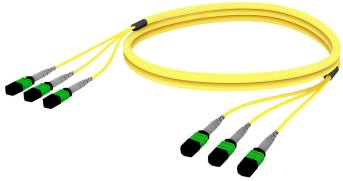

Ultra Low Loss (ULL) Singlemode, MPO8 (Pinned) to MPO8 (Pinned), Ruggedized fanout Cable, 24-Fiber, Low Smoke Zero Halogen (LSZH)

## Product Classification

<b>Regional Availability</b>	Asia   Australia/New Zealand   Europe   Latin America   Middle East /Africa   North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	Ruggedized fanout
<b>Product Brand</b>	SYSTIMAX ULL
<b>Ordering Note</b>	For additional jacket colors, please contact a CommScope Sales Representative   For lengths greater than 999 ft (304 m), orders must be in meters   Minimum length may vary based on cable configuration

## General Specifications

<b>Color, boot A</b>	Gray
<b>Color, connector A</b>	Green
<b>Color, boot B</b>	Gray
<b>Color, connector B</b>	Green
<b>Construction Type</b>	Stranded
<b>Furcation Color</b>	Yellow
<b>Interface, Connector A</b>	MPO-08/APC Male
<b>Interface Feature, connector A</b>	QSFP configuration
<b>Interface, Connector B</b>	MPO-08/APC Male
<b>Interface Feature, connector B</b>	QSFP configuration
<b>Jacket Color</b>	Yellow
<b>Polarity</b>	Method B Enhanced (ULL)
<b>Fibers per Subunit, quantity</b>	8
<b>Total Fibers, quantity</b>	24

## Dimensions


<b>Breakout Length</b>	33 in
------------------------	-------

# UNGQXQXBF

**Cable Assembly Length Range (m)** 3 – 999

**Cable Assembly Length Range (ft)** 10 – 999

## Ordering Tree

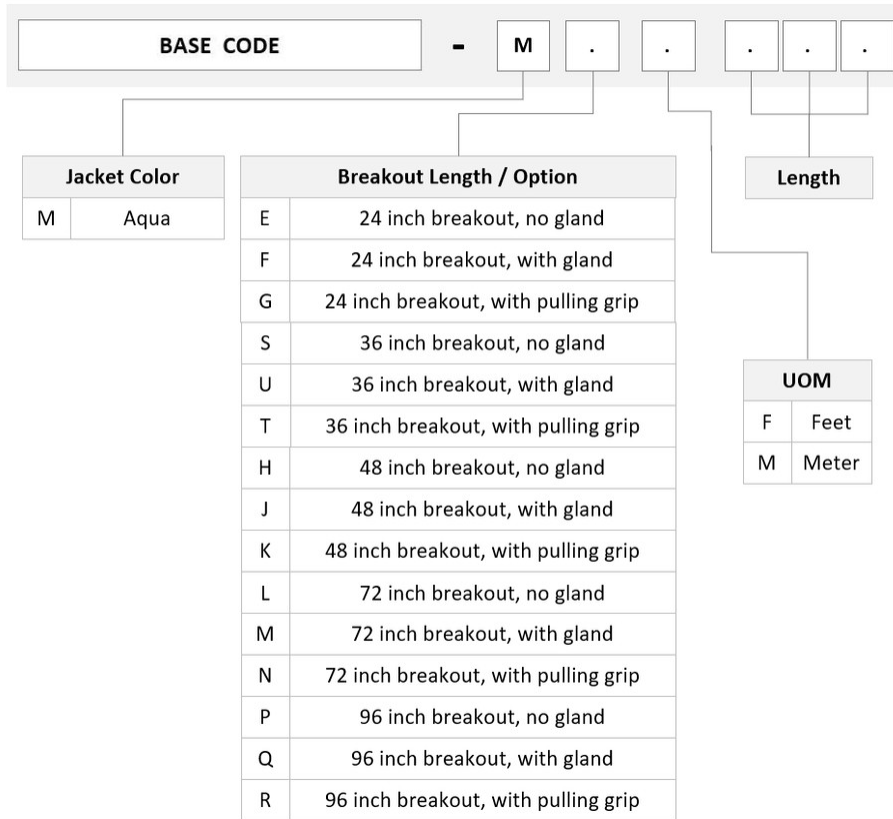

## Mechanical Specifications

**Cable Retention Strength, maximum** 11.24 lb @ 0° | 4.40 lb @ 90°

## Optical Specifications

**Fiber Mode** Singlemode

**Fiber Type** G.657.A2, TeraSPEED®

## Environmental Specifications

**Operating Temperature** -10 °C to +60 °C (+14 °F to +140 °F)

**Environmental Space** Dual Rated LSZH/Riser

# UNGQXQXBF

---

## Regulatory Compliance/Certifications

**Agency**

ANATEL

ISO 9001:2015

**Classification**

Compliant

Designed, manufactured and/or distributed under this quality management system



## Included Products

- |                           |   |  |
|---------------------------|---|--|
| 760248637                 | - | Fiber indoor cable, Low Smoke Zero Halogen Riser MPO Trunk, 24 fiber with 24-fiber, 3.0 mm subunits, Singlemode G.657.A2/B2, Feet jacket marking, Yellow jacket color, B2ca flame rating |
| N-024-MP-8G1-F24YL/30T/B2 |   |  |
| 860637705                 | - | MPO8, ULTRA LOW LOSS, MALE, Singlemode, GREEN, 3mm   |