


UNXQXQXBF

Base Product

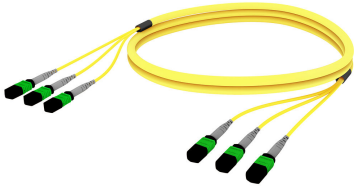

Ultra Low Loss (ULL) OM4 MPO8 (Pinned) to MPO8 (Pinned), Ruggedized fanout Cable, 24-Fiber, Low Smoke Zero Halogen (LSZH)

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Ruggedized fanout
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications


Color, boot A	Gray
Color, connector A	Aqua
Color, boot B	Gray
Color, connector B	Green
Construction Type	Stranded
Furcation Color	Aqua
Interface, Connector A	MPO-08/UPC Male
Interface Feature, connector A	QSFP configuration
Interface, Connector B	MPO-08/UPC Male
Interface Feature, connector B	QSFP configuration
Jacket Color	Aqua
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	8
Total Fibers, quantity	24

UNXQXQXBF

Dimensions

Breakout Length	33 in
Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

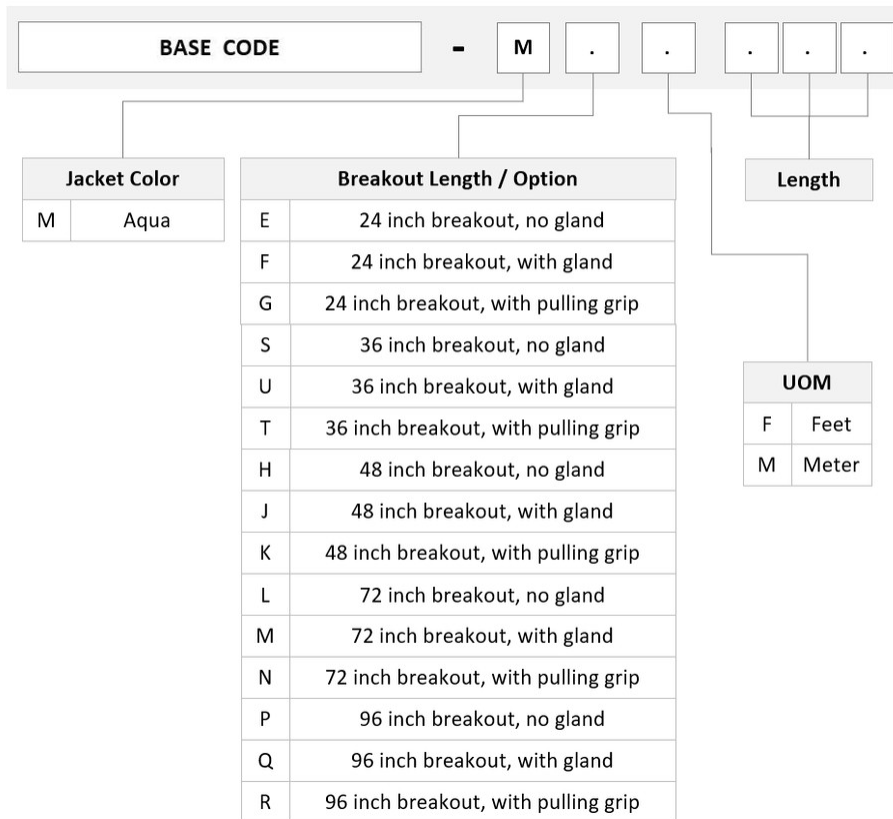

Mechanical Specifications

Cable Retention Strength, maximum	11.24 lb @ 0 ° 4.40 lb @ 90 °
--	---------------------------------

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM4, LazrSPEED®

Environmental Specifications

UNXQXQXBF

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Environmental Space Dual Rated LSZH/Riser

Regulatory Compliance/Certifications

Agency

ANATEL

ISO 9001:2015



Classification

Compliant

Designed, manufactured and/or distributed under this quality management system

Included Products

- 760161794
N-024-MP-5K-F24AQ/D - Fiber Indoor Cable, LazrSPEED® Low Smoke Zero Halogen Riser MPO Trunk Cable, 24 fiber, Gel-free, Multimode OM4, Dca Flame Rating, Feet jacket marking, Aqua jacket color
- 860633308 - MPO8, ULTRA LOW LOSS, MALE, OM3/4, AQUA, 3m