


64624448-144 | O-144-N3-8M-M12NS/PE/PA/PE

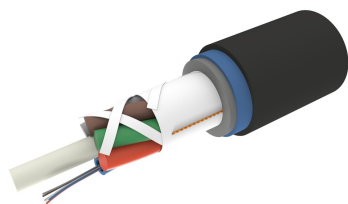

Outdoor Fiber Cable, 144-fiber, singlemode OS2, loose tube s/sheath, black

OBSOLETE

This product was discontinued on: September 24, 2023

Product Classification

Regional Availability	Australia/New Zealand
Portfolio	CommScope®
Product Type	Fiber OSP cable
Product Series	O-N3

General Specifications

Cable Type	Loose tube
Subunit Type	Gel-filled
Jacket Color	Black
Jacket Marking	Meters
Total Fiber Count	144

Dimensions

Diameter Over Jacket	14.3 mm 0.563 in
----------------------	--------------------

Material Specifications

Jacket Material	Nylon
-----------------	-------

Mechanical Specifications

Flex	25 cycles
------	-----------

Optical Specifications

Fiber Type	OS2
------------	-----

Optical Specifications, Wavelength Specific

Standards Compliance

TIA-492CAAB (OS2)

Environmental Specifications

Operating Temperature

-10 °C to +70 °C (+14 °F to +158 °F)

Environmental Space

Buried

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



* Footnotes

Operating Temperature

Specification applicable to non-terminated bulk fiber cable