

## PIM Guard SnapTak Hanger: SSH-3642


for 36-42mm cables

Bulletin 7860089

Revision B

Page 1 of 1

**1**

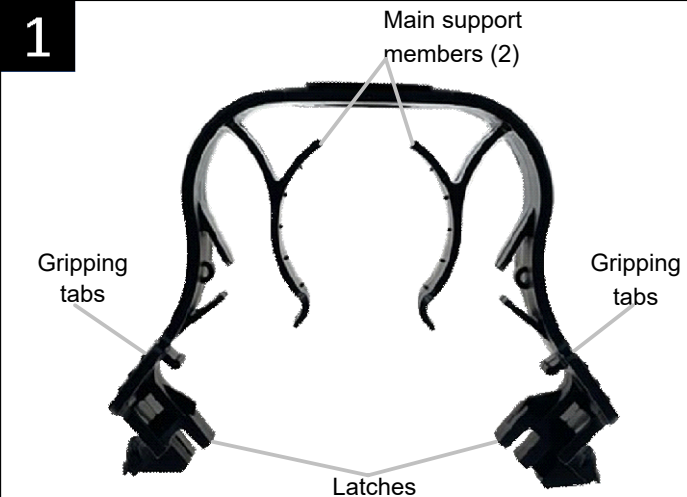

Main support members (2)

Gripping tabs

Latches

The SnapTak hanger has two main support members to engage the cable.

**2**




Insert cable between main support members.

**3**



Squeeze gripping tabs and insert SnapTak adjustable cable hanger into 3/4 inch hole. Polymer SnapTak hangers may be snapped into any other Andrew Snap-in hangers or adapters.

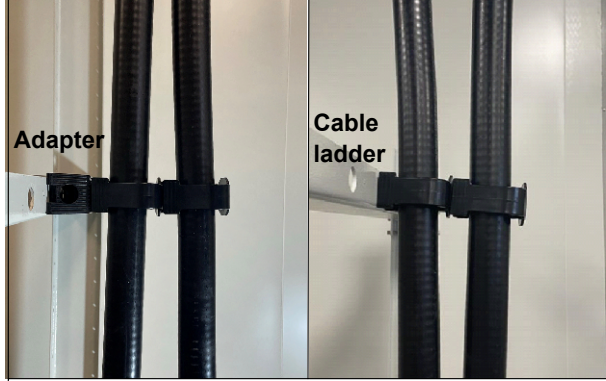


Adapter

Cable ladder

Typical acceptable stack combinations.

**4**

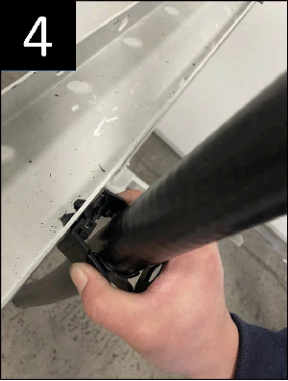

Squeeze gripping tabs to remove SnapTak adjustable cable hanger.

**⚠ WARNING** Be careful not to damage latches when the hanger is installed and removed from the hole.

| Part Information for Available Hangers |              |                                    |
|----------------------------------------|--------------|------------------------------------|
| Part Number                            | Stackability | Cable Diameter Range mm(in)        |
| SSH-3642                               | 2            | 36.00(1.41) min to 42.00(1.65) max |