

ULGLUUCRF

Base Product

Ultra Low Loss (ULL) Singlemode LC/UPC Uniboot to Unconnectorized Ruggedized fanout Cable, 24-Fiber, Rollable Ribbon, Plenum

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Ruggedized fanout
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration


General Specifications

Color, boot A	Blue
Color, connector A	Green
Construction Type	Rollable ribbon
Furcation Color	Yellow
Interface, Connector A	LC/UPC
Interface Feature, connector A	Uniboot
Interface, Connector B	Unterminated
Jacket Color	Yellow
Total Fibers, quantity	24

Dimensions

Cable Assembly Length Range (ft)	150 – 650
----------------------------------	-----------

Ordering Tree

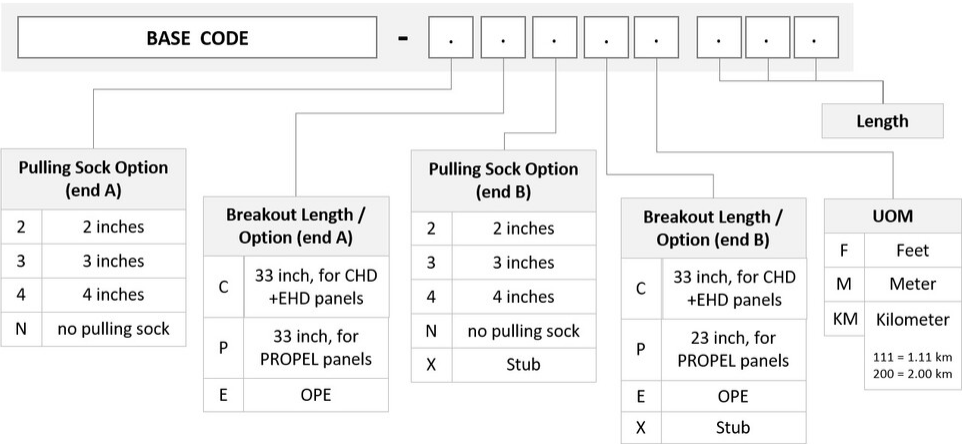

Optical Specifications

Fiber Mode	Singlemode
Fiber Type	G.657.A2, TeraSPEED®

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space	Indoor Plenum

Regulatory Compliance/Certifications

Agency	Classification
ANATEL	Compliant
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant



Included Products

760251512	Indoor Plenum Rollable Ribbon Backbone Cable
P-024-MP-RR-F12YL/8G1/99N	
860658160	LC/UPC Uniboot Connector, Singlemode, Blue