


UJGMPMPRY

Base Product

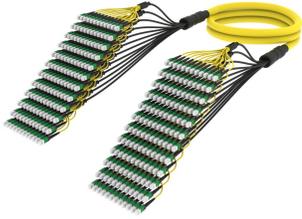

Ultra Low Loss Singlemode MPO12 (Unpinned) to MPO12 (Unpinned)
Pre-terminated Trunk Cable, 1728-Fiber, 12-Fiber Rollable Ribbon Central
Tube, Low Smoke Zero Halogen/Riser

Product Classification

Regional Availability	Asia Australia/New Zealand Europe Latin America Middle East /Africa North America
Portfolio	CommScope®
Product Type	Fiber trunk cable assembly
Product Brand	SYSTIMAX ULL
Ordering Note	For additional jacket colors, please contact a CommScope Sales Representative For lengths greater than 999 ft (304 m), orders must be in meters Minimum length may vary based on cable configuration

General Specifications

Color, boot A	Black
Color, connector A	Green
Color, boot B	Black
Color, connector B	Green
Construction Type	Rollable ribbon
Furcation Color	Yellow
Interface, Connector A	MPO-12/APC Female
Interface, Connector B	MPO-12/APC Female
Jacket Color	Black
Polarity	Method B Enhanced (ULL)
Fibers per Subunit, quantity	12
Total Fibers, quantity	1728

Dimensions

Cable Assembly Length Range (m)	30 – 999
Cable Assembly Length Range (ft)	98 – 999
Cable Assembly Length Range (km)	1.00 – 2.00

UJGMPMPRY



Included Products

- 860638318 - MPO12, ULTRA LOW LOSS, FEMALE, Singlemode, GREEN, 3mm