

FSXLCUCW6

Base Product



LazrSPEED® 550 LC/UPC to Unconnectorized, Distribution Cable, 6-Fiber, Plenum

Product Classification

Regional Availability	North America
Portfolio	CommScope®
Product Type	Fiber distribution cable assembly
Product Brand	SYSTIMAX InstaPATCH® 360
Ordering Note	For lengths greater than 999 ft (304 m), orders must be in meters

General Specifications


Connector A, quantity	6
Color, connector A	Black
Construction Type	Distribution, indoor
Interface, Connector A	LC/UPC
Interface, Connector B	LC/UPC
Jacket Color	Aqua
Total Fibers, quantity	6

Dimensions

Cable Assembly Length Range (m)	3 – 999
Cable Assembly Length Range (ft)	10 – 999

Ordering Tree

FSXLCUCW6

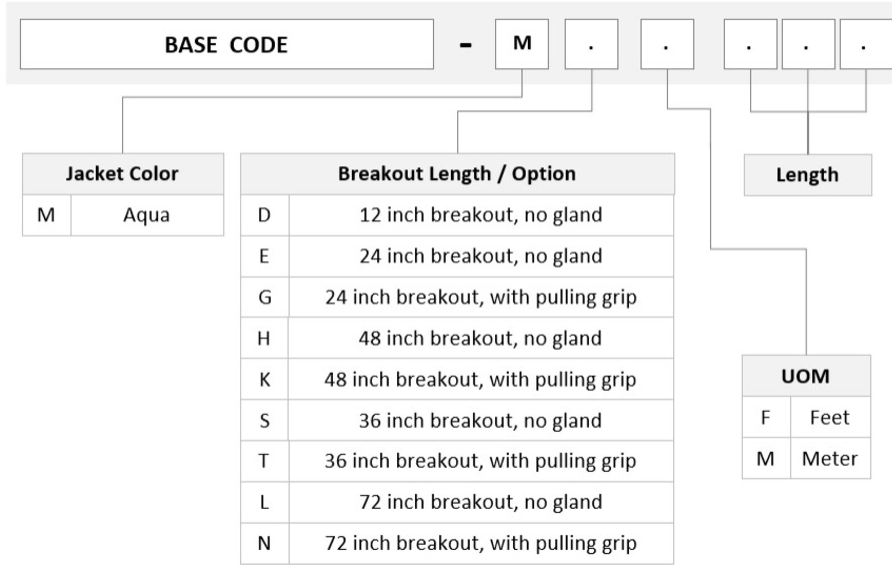

Mechanical Specifications

Cable Retention Strength, maximum 0.50 lb @ 0° | 0.50 lb @ 90°

Optical Specifications

Fiber Mode Multimode

Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature 0 °C to +70 °C (+32 °F to +158 °F)

Environmental Space Indoor | Plenum

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant/Exempted
UK-ROHS	Compliant/Exempted



FSXLCUCW6

Included Products

- 460125271 – Behind The Wall Pre-Radiused LC Connector for 0.9 mm Fiber, multimode
- 760012138 – Fiber indoor cable, LazrSPEED® Plenum Distribution Cable, 6 fiber single-unit, Multimode OM4,
P-006-DS-5K-FSUAQ Feet jacket marking, Aqua jacket color