

# 224597-000 | OCFPS1U-DDQ1204L2-2T-U23

---



OCFPS Fiber Optic DWDM Panel, demux, 40 channels, 1561.42 nm starting wavelength, 100 GHz channel spacing, upgrade port, LC/APC, 1U, 19 in, gray

## Product Classification

<b>Regional Availability</b>	North America
<b>Portfolio</b>	CommScope®
<b>Product Type</b>	DWDM patch panel
<b>Product Series</b>	OCFPS

## General Specifications

<b>Device Type</b>	Patch panel
<b>Functionality</b>	Demultiplexing
<b>Technology Type</b>	Thin film filter (TFF)
<b>Circuits, quantity</b>	1
<b>Distribution Type</b>	40-channel DWDM
<b>Interface, front</b>	LC/APC
<b>Multiplexers, quantity</b>	1
<b>Port Type, optional</b>	Test port (2)   Upgrade port
<b>Rack Units</b>	1


## Dimensions

<b>Height</b>	43.5 mm   1.713 in
<b>Width</b>	440 mm   17.323 in
<b>Depth</b>	210 mm   8.268 in

## Ordering Tree

# 224597-000 | OCFPS1U-DDQ1204L2-2T-U23

## OCFPS 1U - X X X X X X

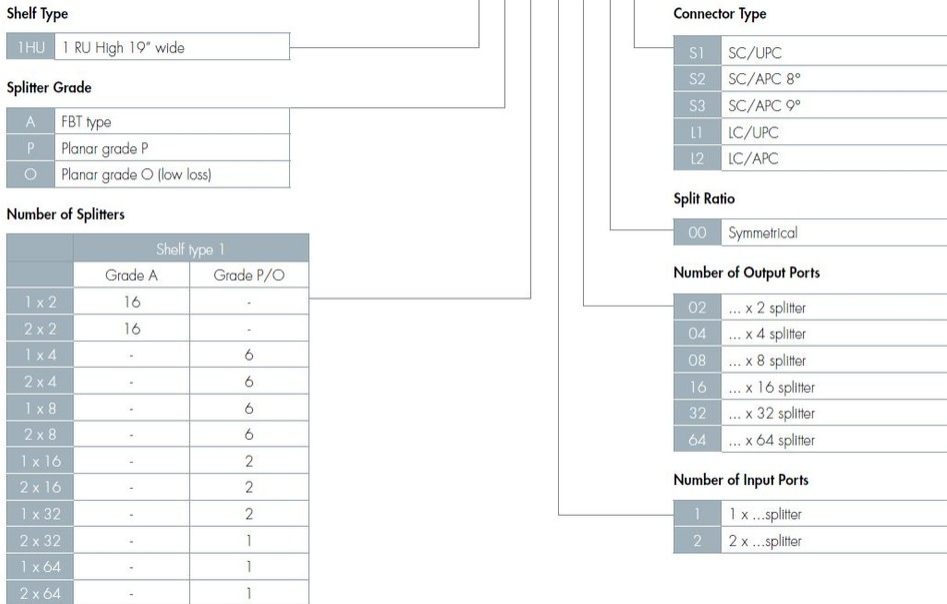

## Optical Specifications

<b>Channel Spacing</b>	100 GHz
<b>Starting Wavelength</b>	1,561.42 nm

## Packaging and Weights

<b>Packaging quantity</b>	1
---------------------------	---

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
REACH-SVHC	Compliant as per SVHC revision on <a href="http://www.commscope.com/ProductCompliance">www.commscope.com/ProductCompliance</a>
ROHS	Compliant
UK-ROHS	Compliant

