


760245723 | CHD12-DM-12LC-LS-B-ULL

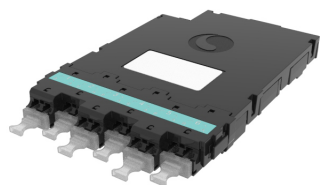

CHD ULL Multimode MPO-12 distribution module, 12LC to 1x12f MPO unpinned, dust plugs

Product Classification

Regional Availability	Asia Australia/New Zealand EMEA Latin America North America
Portfolio	CommScope®
Product Type	Fiber module
Product Brand	SYSTIMAX ULL
Product Series	CHD

General Specifications

Functionality	Breakout
Color, front	Aqua
Color, rear	Gray
Interface, front	LC/UPC
Interface, rear	MPO
Interface Feature, rear	Key up/up MPO Non-Pinned
Polarity	Method B Enhanced (ULL)
Shuttered	No
Total Fibers, quantity	12

Dimensions

Height	12.45 mm 0.49 in
Width	83.82 mm 3.3 in
Depth	131.83 mm 5.19 in

Optical Specifications

Fiber Mode	Multimode
Fiber Type	OM4, LazrSPEED® 550
Insertion Loss, maximum	0.35 dB

760245723 | CHD12-DM-12LC-LS-B-ULL

Environmental Specifications

Qualification Standards IEC 61753-1 | TIA-568.3-D

Safety Standard CE | CSA | UL

Packaging and Weights

Packaging quantity 1

Weight, net 0.082 kg | 0.18 lb

Regulatory Compliance/Certifications

Agency

Classification

CHINA-ROHS

Below maximum concentration value

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

REACH-SVHC

Compliant as per SVHC revision on www.commscope.com/ProductCompliance

ROHS

Compliant

UK-ROHS

Compliant

