


FSXLCLCWH

Base Product

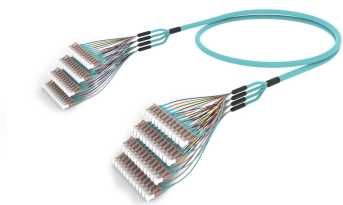

LazrSPEED® 550 LC/UPC to LC/UPC, Distribution Cable, 48-Fiber, Plenum

Product Classification

| | |
|-----------------------|---|
| Regional Availability | North America |
| Portfolio | CommScope® |
| Product Type | Fiber distribution cable assembly |
| Product Brand | SYSTIMAX InstaPATCH® 360 |
| Ordering Note | For lengths greater than 999 ft (304 m), orders must be in meters |


General Specifications

| | |
|------------------------|----------------------|
| Cable Glands | No glands |
| Color, connector A | Beige |
| Color, connector B | Beige |
| Construction Type | Distribution, indoor |
| Interface, Connector A | LC/UPC |
| Interface, Connector B | LC/UPC |
| Total Fibers, quantity | 48 |

Dimensions

| | |
|----------------------------------|---------|
| Cable Assembly Length Range (m) | 3 – 305 |
| Cable Assembly Length Range (ft) | 7 – 999 |

Ordering Tree

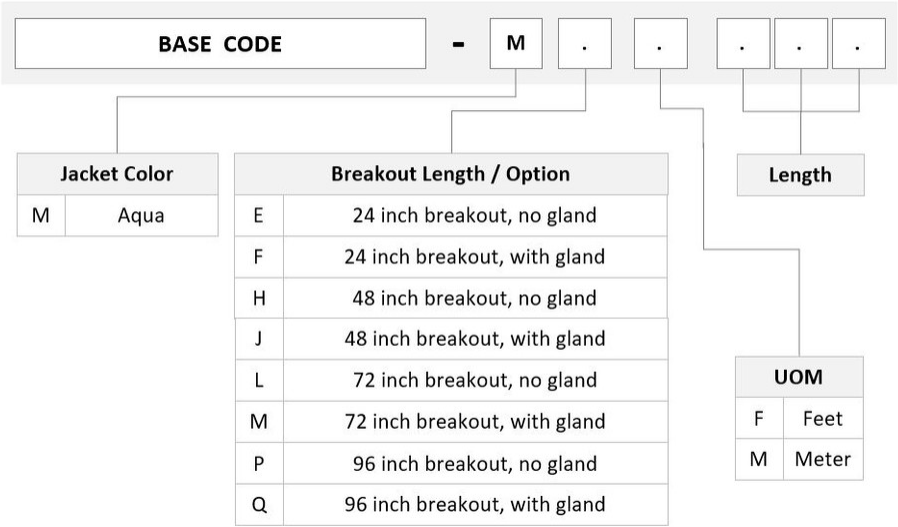

Mechanical Specifications

Cable Retention Strength, maximum 0.50 lb @ 0 ° | 0.50 lb @ 90 °

Optical Specifications

Fiber Mode Multimode
Fiber Type OM4, LazrSPEED®

Environmental Specifications

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)
Environmental Space Plenum

Regulatory Compliance/Certifications

| Agency | Classification |
|---------------|--|
| CHINA-ROHS | Below maximum concentration value |
| ISO 9001:2015 | Designed, manufactured and/or distributed under this quality management system |
| REACH-SVHC | Compliant as per SVHC revision on www.commscope.com/ProductCompliance |
| ROHS | Compliant |
| UK-ROHS | Compliant |



Included Products

- | | | |
|-----------------|---|--|
| 460125271 | – | Behind The Wall Pre-Radiused LC Connector for 0.9 mm Fiber, multimode |
| P-048-DS-5K-FMU | – | Fiber indoor cable, LazrSPEED® Plenum Distribution, 48-Fiber Multi-Unit with 12-Fiber Subunits, Multimode OM4, Gel-free, Feet jacket marking |