

760244780 | VCM-DS-84-8B



Vertical Cable Management Kit, 8in X 84in (203mm X 2134mm) Double Sided, With Doors, Black

Product Classification

Regional Availability Asia | Australia/New Zealand | EMEA | Latin America | North America
Portfolio CommScope®
Product Type Vertical cable management

General Specifications


Configuration Type Double-sided
Color Black
Door, quantity 2

Dimensions

Height 2,133.6 mm | 84 in
Width 203.2 mm | 8 in
Depth 558.8 mm | 22 in

Trough Capacity

Ordered Installation - 40%						
VCM Width	Cat 5e		Cat 6		Cat 6A	
	Front Trough	Rear Trough	Front Trough	Rear Trough	Front Trough	Rear Trough
6 in	492	492	397	397	248	248
8 in	671	671	541	541	338	338
10 in	850	850	685	685	429	429
12 in	1029	1029	829	829	518	518
Randomized Installation - 20%						
VCM Width	Cat 5e		Cat 6		Cat 6A	
	Front Trough	Rear Trough	Front Trough	Rear Trough	Front Trough	Rear Trough
6 in	246	246	198	198	124	124
8 in	335	335	270	270	169	169
10 in	425	425	343	343	214	214
12 in	514	514	415	415	259	259

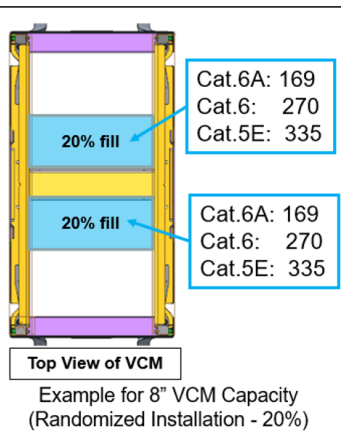

Material Specifications

760244780 | VCM-DS-84-8B

Finish	Powder-coated, smooth
Material Type	Metal

Environmental Specifications

Safety Standard	UL cUL
------------------------	----------

Packaging and Weights

Included	Four 1/2-20 hex nuts Four 1/2-20 x 1 in hex head bolts Four flat washers Instruction sheet
Packaging quantity	1
Packaging Type	Assembled
Weight, net	30.391 kg 67 lb

Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Below maximum concentration value
ISO 9001:2015	Designed, manufactured and/or distributed under this quality management system
REACH-SVHC	Compliant as per SVHC revision on www.commscope.com/ProductCompliance
ROHS	Compliant
UK-ROHS	Compliant

