


# L-LN

Base Product

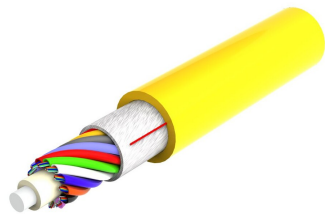

Fiber Optic Cable, Indoor Zero Halogen, CPR-only flame rated, Stranded Loose Tube All-Dielectric

- CommScope’s indoor fiber cables are positioned for Data Center or Central Office applications
- Superior mechanical and optical performance with unmatched stability and quality
- Available Jacket Colors: Aqua and Yellow


## Product Classification

Regional Availability	Asia   Australia/New Zealand   EMEA   Latin America   North America
Portfolio	CommScope®
Product Type	Fiber indoor cable
Product Series	L-LN

## General Specifications

Cable Type	Stranded microsheath tube
Construction Type	Non-armored
Subunit Type	Gel-free
Jacket Marking Text	MFOG20074D/CC OXG INDOORKABEL COMMScope OPTICAL CABLE 760244553 [MM/YYYY] 048 EN 50575 CLASS D [SERIAL NUMBER] [METRE MARK]

## Ordering Tree

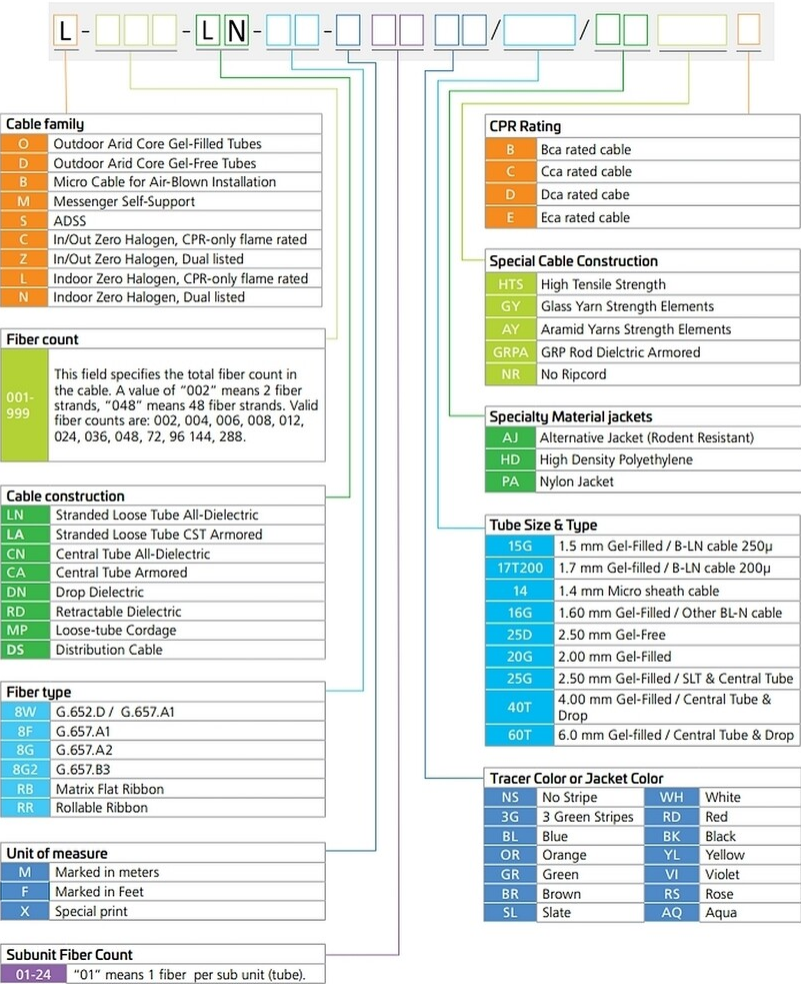

Material Specifications

Inner Jacket Material Low Smoke Zero Halogen (LSZH)

Environmental Specifications

Installation temperature 0 °C to +50 °C (+32 °F to +122 °F)

Operating Temperature -10 °C to +60 °C (+14 °F to +140 °F)

Storage Temperature -40 °C to +70 °C (-40 °F to +158 °F)

Environmental Space Low Smoke Zero Halogen (LSZH)

\* Footnotes

Operating Temperature Specification applicable to non-terminated bulk fiber cable