


760253193 | M4800-DDM

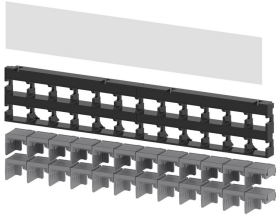

M4800 DDM for M-series Jacks, Black (MGS600 / MGS400 / UNJ10GT), Black

Product Classification

Regional Availability	Asia Europe Latin America
Portfolio	CommScope®
Product Type	Bezel
Product Series	M Series

General Specifications

Color Black

Dimensions

Height	43.688 mm 1.72 in
Width	229.108 mm 9.02 in
Depth	17.018 mm 0.67 in

Material Specifications

Material Type High-impact, flame retardant, thermoplastic

Environmental Specifications

Operating Temperature	-10 °C to +60 °C (+14 °F to +140 °F)
Storage Temperature	-40 °C to +70 °C (-40 °F to +158 °F)
Relative Humidity	Up to 95%, non-condensing
Flammability Rating	UL 94 V-0

Packaging and Weights

Packaging quantity 1

Regulatory Compliance/Certifications

Agency	Classification
--------	----------------

760253193 | M4800-DDM

ISO 9001:2015

Designed, manufactured and/or distributed under this quality management system

