



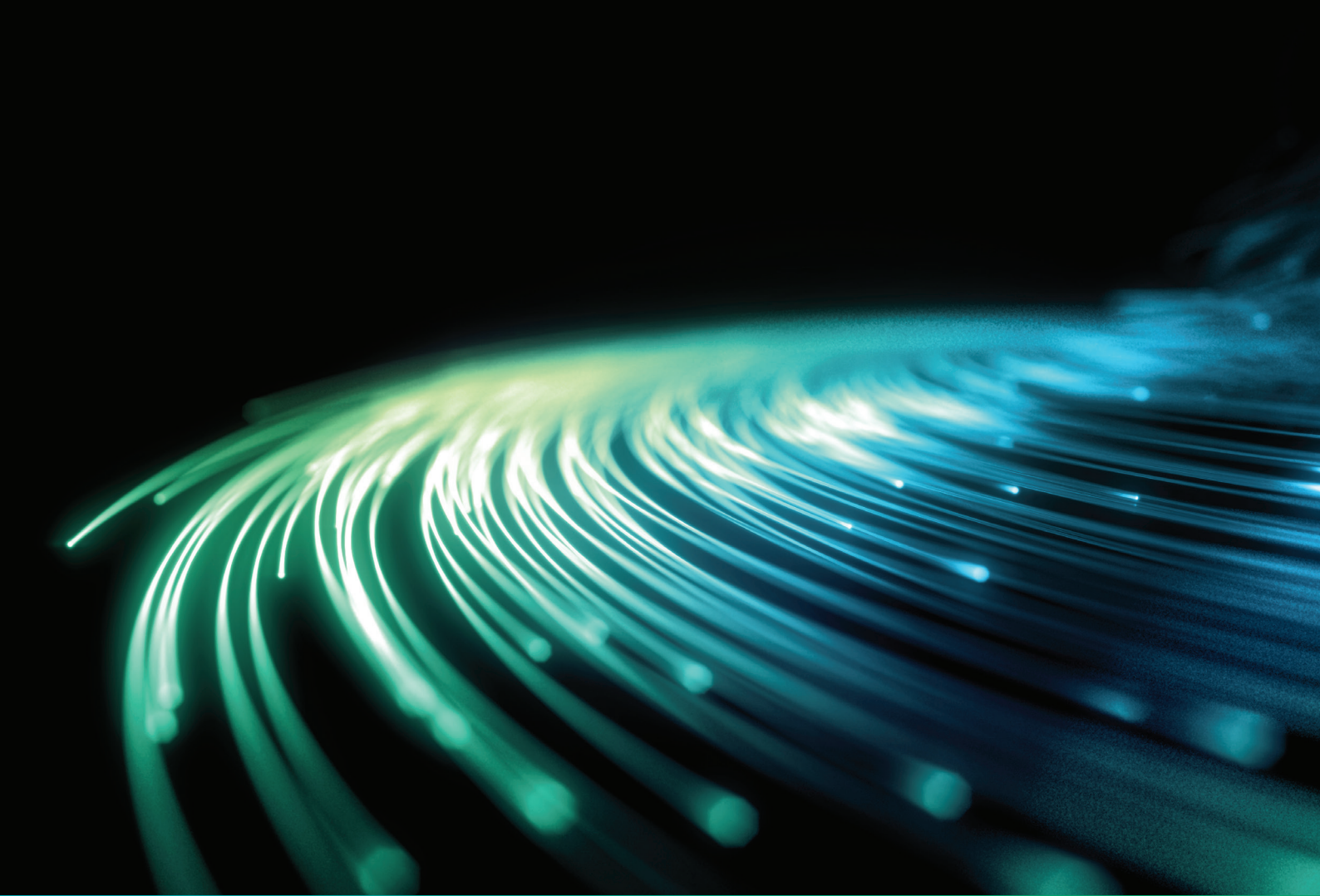

康普中国——光纤光缆热点产品手册

COMMScope®

室内外通用LSZH光缆

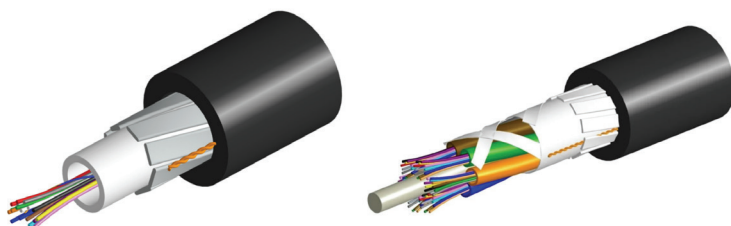

室内外通用LSZH光缆

光纤芯数	单模G652D & G.657.A1		OM3		OM4	
	公共码	产品型号	公共码	产品型号	公共码	产品型号
2	760255146	C-002-CN-8Z-M04BK/28G/09X	760256831	C-002-CN-5Y-M02BK/28G/09X	760256843	C-002-CN-5X-M02BK/28G/09X
4	760255147	C-004-CN-8Z-M04BK/28G/09X	760256832	C-004-CN-5Y-M04BK/28G/09X	760256844	C-004-CN-5X-M04BK/28G/09X
6	760255148	C-006-CN-8Z-M06BK/28G/09X	760256833	C-006-CN-5Y-M06BK/28G/09X	760256845	C-006-CN-5X-M06BK/28G/09X
8	760255149	C-008-CN-8Z-M08BK/28G/09X	760256834	C-008-CN-5Y-M08BK/28G/09X	760256846	C-008-CN-5X-M08BK/28G/09X
12	760255150	C-012-CN-8Z-M12BK/28G/09X	760256835	C-012-CN-5Y-M12BK/28G/09X	760256847	C-012-CN-5X-M12BK/28G/09X
24	760255151	C-024-CN-8Z-M24BK/35G/09X	760256836	C-024-CN-5Y-M24BK/35G/09X	760256848	C-024-CN-5X-M24BK/35G/09X
24	760255152	C-024-LN-8Z-M06BK/18G/09X	760256837	C-024-LN-5Y-M06BK/18G/09X	760256849	C-024-LN-5X-M06BK/18G/09X
36	760255153	C-036-LN-8Z-M12BK/21G/09X	760256838	C-036-LN-5Y-M12BK/21G/09X	760256850	C-036-LN-5X-M12BK/21G/09X
48	760255154	C-048-LN-8Z-M12BK/21G/09X	760256839	C-048-LN-5Y-M12BK/21G/09X	760256851	C-048-LN-5X-M12BK/21G/09X
72	760256357	C-072-LN-8Z-M12BK/21G/09X	760256840	C-072-LN-5Y-M12BK/21G/09X	760256852	C-072-LN-5X-M12BK/21G/09X
96	760256358	C-096-LN-8Z-M12BK/21G/09X	760256841	C-096-LN-5Y-M12BK/21G/09X	760256853	C-096-LN-5X-M12BK/21G/09X
144	760256830	C-144-LN-8Z-M12BK/21G/09X	760256842	C-144-LN-5Y-M12BK/21G/09X	760256854	C-144-LN-5X-M12BK/21G/09X

光缆主要规格

光纤芯数 (套管数量x每个套管的光纤数量)	2~24 (1x2/4/6/8/12/24)	24 (6x6)	36,48,72 (6x12)	96 (8x12)	144 (12x12)
光缆外径 mm	7.0±0.5	10.0±0.5	10.7±0.5	12.0±0.6	14.7±0.8
重量kg/km	58	107	117	143	213
最小弯曲半径 (mm)	安装20 x Cable Ø, 长期10 x Cable Ø				
最大拉力 (N)	安装800/长期400	安装1500/长期600			
短期抗压 (N/100mm)	1000	1500			

光纤熔接配线架


FMS光纤熔接配线架，箱体有导轨可滑动抽出，可以安装在19英寸机架或机柜内，在工厂预装了适配器、尾纤、熔接托盘、熔接保护管和其他附件。



FMS光纤熔接配线架

产品公共码	产品型号	产品描述
760254122	FMS-K1BI-S1A1-12-SP	FMS Panel, 1U, 19 in, black, Includes 6 x SC SM Duplex Adaptors (12F), 12 x SM SC Pigtails. 12 x Splice protectors. Splice tray and cable glands
760254435	FMS-K2BI-S1A1-24-SP	FMS Panel, 1U, 19 in, black, Includes 12 x SC SM Duplex Adaptors (24F), 24 x SM SC Pigtails. 24 x Splice protectors. Splice tray and cable glands
760254436	FMS-K1BI-L1A1-12-SP	FMS Panel, 1U, 19 in, black, Includes 6 x LC SM Duplex Adaptors (12F), 12 x SM LC Pigtails. 12 x Splice protectors. Splice tray and cable glands
760254437	FMS-K2BI-L1A1-24-SP	FMS Panel, 1U, 19 in, black, Includes 12 x LC SM Duplex Adaptors (24F), 24 x SM LC Pigtails. 24 x Splice protectors. Splice trays (2) and cable glands
760254438	FMS-K2BI-L1A1-48-SP	FMS Panel, 1U, 19 in, black, Includes 24 x LC SM Duplex Adaptors (48F), 48 x SM LC Pigtails. 48 x Splice protectors. Splice trays (2) and cable glands
760254439	FMS-K1BI-SOM4-12-SP	FMS Panel, 1U, 19 in, black, Includes 6 x SC OM4 Duplex Adaptors (12F), 12 x OM4 SC Pigtails. 12 x Splice protectors. Splice tray and cable glands
760254440	FMS-K2BI-SOM4-24-SP	FMS Panel, 1U, 19 in, black, Includes 12 x SC OM4 Duplex Adaptors (24F), 24 x OM4 SC Pigtails. 24 x Splice protectors. Splice tray and cable glands
760254441	FMS-K1BI-LOM4-12-SP	FMS Panel, 1U, 19 in, black, Includes 6 x LC OM4 Duplex Adaptors (12F), 12 x OM4 LC Pigtails. 12 x Splice protectors. Splice tray and cable glands
760254442	FMS-K2BI-LOM4-24-SP	FMS Panel, 1U, 19 in, black, Includes 12 x LC OM4 Duplex Adaptors (24F), 24 x OM4 LC Pigtails. 24 x Splice protectors. Splice trays (2) and cable glands
760254443	FMS-K2BI-LOM4-48-SP	FMS Panel, 1U, 19 in, black, Includes 24 x LC OM4 Duplex Adaptors (48F), 48 x OM4 LC Pigtails. 48 x Splice protectors. Splice trays (2) and cable glands


光纤跳线和尾纤

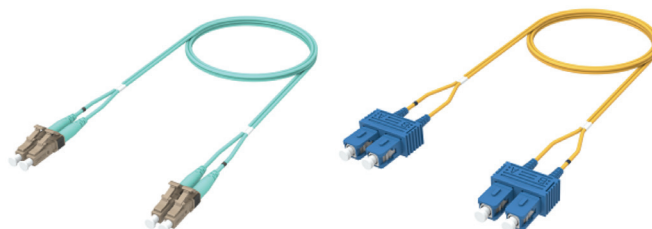

CEP LC/SC双工光纤跳线

光缆类型: 1.8mm LSZH Zip Cable

光缆类型	光纤类型	接头类型	产品型号	产品描述
2F Yellow 1.8mm LSZH zipcable GB31247-B1	SM G.657.A2	LC-LC Duplex	CEP-LCLC-LS0BxxxM	CEP Jumper LC-LC SM LSZH 1.8mm DX xxxM
		LC-SC Duplex	CEP-LCSC-LS0BxxxM	CEP Jumper LC-SC SM LSZH 1.8mm DX xxxM
		SC-SC Duplex	CEP-SCSC-LS0BxxxM	CEP Jumper SC-SC SM LSZH 1.8mm DX xxxM
2F AQUA 1.8mm LSZH zipcable GB31247-B1	OM4	LC-LC Duplex	CEP-LCLC-L40BxxxM	CEP Jumper LC-LC OM4 LSZH 1.8mm DX xxxM
		LC-SC Duplex	CEP-LCSC-L40BxxxM	CEP Jumper LC-SC OM4 LSZH 1.8mm DX xxxM
		SC-SC Duplex	CEP-SCSC-L40BxxxM	CEP Jumper SC-SC OM4 LSZH 1.8mm DX xxxM
2F AQUA 1.8mm LSZH zipcable GB31247-B1	OM3	LC-LC Duplex	CEP-LCLC-L30BxxxM	CEP Jumper LC-LC OM3 LSZH 1.8mm DX xxxM
		LC-SC Duplex	CEP-LCSC-L30BxxxM	CEP Jumper LC-SC OM3 LSZH 1.8mm DX xxxM
		SC-SC Duplex	CEP-SCSC-L30BxxxM	CEP Jumper SC-SC OM3 LSZH 1.8mm DX xxxM
2F Yellow 1.8mm Plenum zipcable	SM G.657.A2	LC-LC Duplex	CEP-LCLC-PS0BxxxM	CEP Jumper LC-LC SM Plenum 1.8mm DX xxxM
2F AQUA 1.8mm Plenum zipcable	OM4	LC-LC Duplex	CEP-LCLC-P40BxxxM	CEP Jumper LC-LC OM4 Plenum 1.8mm DX xxxM

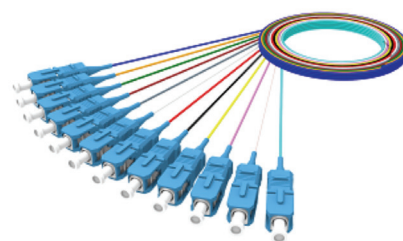

OCP-AP光纤尾纤

光缆类型	光纤类型	接头类型	产品公共码	产品型号
1F 0.9mm LSZH Semi-tight butter cable	SM G.657.A1	SC/UPC-stub	EH0108-001	OCP-S1-15DASEN-XX-AP
		SC/APC-stub	EH0108-002	OCP-S2-15DASEN-XX-AP
		LC/UPC-stub	EH0108-003	OCP-L1-15DASEN-XX-AP
		LC/APC-stub	EH0108-004	OCP-L2-15DASEN-XX-AP
	OM4	SC/UPC-stub	EH0108-007	OCP-S5-15DGSEN-XX-AP
		LC/UPC-stub	EH0108-008	OCP-L5-15DGSEN-XX-AP
12-Color Kit 0.9mm LSZH Semi-tight butter cable	SM G.657.A1	SC/UPC-stub	EH0194-001	OCP-S1-15DASEN-XX-(12)-AP
		SC/APC-stub	EH0194-002	OCP-S2-15DASEN-XX-(12)-AP
		LC/UPC-stub	EH0194-003	OCP-L1-15DASEN-XX-(12)-AP
		LC/APC-stub	EH0194-004	OCP-L2-15DASEN-XX-(12)-AP
	OM4	SC/UPC-stub	EH0194-007	OCP-S5-15DGSEN-XX-(12)-AP
		LC/UPC-stub	EH0194-008	OCP-L5-15DGSEN-XX-(12)-AP

MDS光纤配线架和模块

MDS系列光纤配线架，箱体有导轨可滑动抽出，可以安装在19英寸机架或机柜内，支持MPO to LC模块，适配器模块，以及熔接托盘(760241378 | EPX-SPLICE-48)。




MDS光纤配线架

类型	最大密度	产品型号	产品描述
1U滑动式	1U 96LC	MDS-1U-ENC	MDS 1U Sliding Fiber Panel
1U平面型可折叠	1U 96LC	MDS-1U-OPEN-F	MDS 1U Foldable Fiber Panel Flat
1U角型可折叠	1U 96LC	MDS-1U-OPEN-F-ANG	MDS 1U Foldable Fiber Panel Angled
2U滑动式	2U 192LC	MDS-2U-ENC	MDS 2U Sliding Fiber Panel



MDS MPO to LC 模块 (极性B)

光纤类型	接头类型	产品型号	产品描述
多模	2 x MPO-12 pinned to 24 LC/UPC	MDS-DM-24LC-MM	MDS MPO to LC module OM4 24F
	1 x MPO-12 pinned to 12 LC/UPC	MDS-DM-12LC-MM	MDS MPO to LC module OM4 12F
单模	2 x MPO-12 pinned to 24 LC/UPC	MDS-DM-24LC-SM	MDS MPO to LC module SM 24F
	1 x MPO-12 pinned to 12 LC/UPC	MDS-DM-12LC-SM	MDS MPO to LC module SM 12F

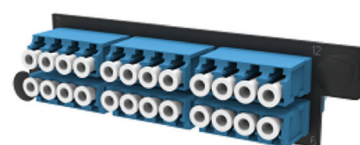

MDS 适配器模块

接口类型	产品型号	产品描述
8 x MPO	MDS-DP-8MPO	MDS adaptor pack 8 MPO Port
4 x MPO	MDS-DP-4MPO	MDS adaptor pack 4 MPO Port
3 x MPO	MDS-DP-3MPO	MDS adaptor pack 3 MPO Port
多模24 LC	MDS-DP-24LC-MM	MDS adaptor pack OM4 24LC
单模24 LC	MDS-DP-24LC-SM	MDS adaptor pack SM 24LC
多模12 LC	MDS-DP-12LC-MM	MDS adaptor pack OM4 12LC
单模12 LC	MDS-DP-12LC-SM	MDS adaptor pack SM 12LC
多模12 SC	MDS-DP-12SC-MM	MDS adaptor pack OM4 12SC
单模12 SC	MDS-DP-12SC-SM	MDS adaptor pack SM 12SC
空面板	MDS-BLANK	MDS BLANK ADAPTER PLATE

CEP MPO预端接光缆



CEP MPO预端接光缆

光缆类型	接头类型	光纤类型	光缆颜色	产品型号
3.0mm 12F LSZH	MPO12 unpinned to MPO12 unpinned	SM G.657.A1	Yellow	CEP-MPMP-LS0ZxxxM
		OM4	Aqua	CEP-MPMP-L40ZxxxM
		OM3	Aqua	CEP-MPMP-L30ZxxxM
3.0mm 12F OFNP	MPO12 unpinned to MPO12 unpinned	SM G.657.A1	Yellow	CEP-MPMP-PS0ZxxxM
		OM4	Aqua	CEP-MPMP-P40ZxxxM
		OM3	Aqua	CEP-MPMP-P30ZxxxM

CEP 可换极性和公母头MPO预端接光缆



光缆类型	接头类型	光纤类型	光缆颜色	产品型号
3.0mm 12F LSZH GB31247-B1	MPO12 unpinned to MPO12 unpinned	OM4	Aqua	CEP-MFMF-L40KxxxM
		SM G.657.A1	Yellow	CEP-MFMF-LS0KxxxM

CEP LC Uniboot光纤跳线



CEP LC Uniboot光纤跳线

光缆类型	光纤类型	接头类型	产品型号	产品描述
2F Yellow 2.0mm LSZH	SM G.657.A2	LC Uniboot - LC Uniboot	CEP-MCMC-LS0HxxxM	CEP Jumper LCU-LCU SM LSZH 2mm xxxM
2F AQUA 2.0mm LSZH	OM4	LC Uniboot - LC Uniboot	CEP-MCMC-L40HxxxM	CEP Jumper LCU-LCU OM4 LSZH 2mm xxxM

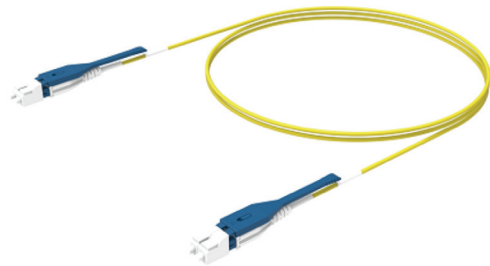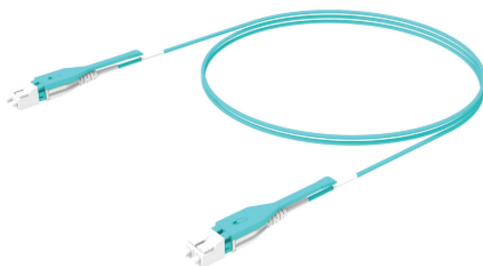

CEP LC Uniboot带拉杆光纤跳线

光缆类型	光纤类型	接头类型	产品型号	产品描述
2F Yellow 2.0mm LSZH	SM G.657.A2	LC Uniboot - LC Uniboot with tab	CEP-MWMW-LS0HxxxM	CEP Jumper LCU-LCU SM LSZH 2mm w T xxxM
2F AQUA 2.0mm LSZH	OM4	LC Uniboot - LC Uniboot with tab	CEP-MWMW-L40HxxxM	CEP Jumper LCU-LCU OM4 LSZH 2mm w T xxxM

CEP ST/FC光纤产品

CEX ST/FC光纤熔接配线架和适配器模块

产品类型	产品型号	产品描述
1U24F 单模 ST 光纤熔接配线	760251744	CEX-1U-ST-SM-24P
1U24F 多模ST 光纤熔接配线	760251745	CEX-1U-ST-OM3-24P
LGX ST 适配器组	760256498	CEX-LGX-012-ST
1U24F 单模 FC 光纤熔接配线	760249401	CEX-1U-FC-SM-24P
1U24F 多模 ST 光纤熔接配线	760249403	CEX-1U-FC-OM3-24P
LGX FC 适配器组	760256499	CEX-LGX-012-FC

CEP ST/FC双工光纤跳线

光缆类型	光纤类型	接头类型	产品型号	产品描述
2F Yellow 1.8mm LSZH zipcable GB31247-B1	SM G.657.A2	ST-ST Duplex	CEP-TCTC-LS0BxxxM	CEP Jumper ST-ST SM LSZH 1.8mm DX xxxM
		LC-ST Duplex	CEP-LCTC-LS0BxxxM	CEP Jumper LC-ST SM LSZH 1.8mm DX xxxM
2F AQUA 1.8mm LSZH zipcable GB31247-B1	OM3	ST-ST Duplex	CEP-TCTC-L30BxxxM	CEP Jumper ST-ST OM3 LSZH 1.8mm DX xxxM
		LC-ST Duplex	CEP-LCTC-L30BxxxM	CEP Jumper LC-ST OM3 LSZH 1.8mm DX xxxM
2F AQUA 1.8mm LSZH zipcable GB31247-B1	OM4	ST-ST Duplex	CEP-TCTC-L40BxxxM	CEP Jumper ST-ST OM4 LSZH 1.8mm DX xxxM
		LC-ST Duplex	CEP-LCTC-L40BxxxM	CEP Jumper LC-ST OM4 LSZH 1.8mm DX xxxM
2F Yellow 1.8mm LSZH zipcable GB31247-B1	SM G.657.A2	FC-FC Duplex	CEP-FCFC-LS0BxxxM	CEP Jumper FC-FC SM LSZH 1.8mm DX xxxM
		LC-FC Duplex	CEP-LCFC-LS0BxxxM	CEP Jumper LC-FC SM LSZH 1.8mm DX xxxM
		SC-FC Duplex	CEP-SCFC-LS0BxxxM	CEP Jumper SC-FC SM LSZH 1.8mm DX xxxM
2F AQUA 1.8mm LSZH zipcable GB31247-B1	OM3	FC-FC Duplex	CEP-FCFC-L30BxxxM	CEP Jumper FC-FC OM3 LSZH 1.8mm DX xxxM
		LC-FC Duplex	CEP-LCFC-L30BxxxM	CEP Jumper LC-FC OM3 LSZH 1.8mm DX xxxM

CEP ST/FC 光纤尾纤

光缆类型	接头类型	光纤类型	产品公共码	产品型号
1F 0.9mm pigtail	ST-stub	SM G.657.A1	760246263	CEP-TC00-050E001M
		OM3	760246261	CEP-TC00-030E001M
	FC-stub	SM G.657.A1	760251940	CEP-FC00-150E001M
		OM3	760252380	CEP-FC00-130E001M

康普通过创意构想和突破性发现，推动通信技术的发展。这些构想和发现均足以激发伟大的人类成就。我们与客户和合作伙伴合作设计、创造并构建世界先进网络。发现新的机遇并实现更美好的明天是我们的激情和承诺。了解更多信息，请访问 zh.commscope.com。

康普公司（全球总部）

地址：1100 CommScope Place,
SE Hickory NC 28602, 美国
电话：+1 828 324 2200

业务联系方式

康普电讯（上海）有限公司

北京办公室

地址：北京市东城区建国门南大街 7 号
璞邸酒店 C 座 6 层 605 室
邮编：100005
电话：010-8593 7300

上海办公室

地址：上海市闵行区吴中路 1799 号
万象城 B 座 2 楼
邮编：201103
电话：021-8022 3300

广州办公室

地址：广州市天河区珠江新城华夏路 30 号
富力盈通大厦 701 室
邮编：510623
电话：020-8715 5800

武汉办公室

地址：武汉市洪山区珞狮南路（文荟街交叉口）
星光时代大厦 10 楼 1003 号
邮编：430079
电话：027-8768 8258, 8768 8558

深圳办公室

地址：深圳市南山区科苑路科技园
金融基地 2 栋 5 楼 F 单元
邮编：518057
电话：0755-2639 6610

CommScope Solutions International Inc.

地址：香港九龙观塘观塘道 388 号创纪之城
1 座 8 楼 811-18 室
电话：+852-2515 7500

CommScope Technologies LLC Taiwan Branch

地址：新北市板桥区新站路 16 号 38 楼
邮编：22041
电话：+886-02-7753-1599

工厂联系方式

康普科技（苏州）有限公司

地址：江苏省苏州工业园区
出口加工区 B 区
启明路 77 号
邮编：215121
电话：0512-8818 1000

康普通讯技术（中国）有限公司

地址：江苏省苏州工业园区
苏虹西路 68 号
邮编：215021
电话：0512-6761 0069

请关注



@ 康普公司



COMMScope®

zh.commscope.com

如需了解更多信息，请访问我司网站或联系您的康普销售代表。

© 2024 CommScope, LLC. 保留所有权利。
CommScope 及 CommScope 标识是康普公司和 / 或其关联公司在美国及其他国家 / 地区的注册商标。
更多商标信息，请访问 <https://www.commscope.com/trademarks>。产品名称、商标和注册商标均为其各自所有权人的财产。