


# SMU2080-01

---

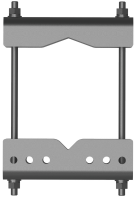

Universal Saddle Mount (single) for straight or tapered legs up to 8 in OD, 8 in angle 60°, or 6 in angle 90°

## Product Classification

**Product Type** Saddle mount

## General Specifications

**Mounting** Angle 60°, 203.2 mm (8 in) | Angle 90°, 152.4 mm (6 in) | Straight or tapered legs up to 203.2 mm (8 in) OD

**Tower Taper** Non-tapered | Tapered

## Dimensions

**Height** 152.4 mm | 6 in

**Width** 304.8 mm | 12 in

**Length** 457.2 mm | 18 in

**Mounting Diameter, maximum** 203.2 mm | 8 in

**Mounting Diameter, minimum** 38.1 mm | 1.5 in

## Material Specifications

**Material Type** Hot dip galvanized steel

## Packaging and Weights

**Included** Mount

**Packaging quantity** 1

**Weight, net** 12.6 kg | 27.778 lb

## Regulatory Compliance/Certifications

Agency	Classification
CHINA-ROHS	Above maximum concentration value

# SMU2080-01

---

ROHS Compliant/Exempted

UK-ROHS Compliant/Exempted

